


# E10987



## Connection cable

VDOGF030MSS0002H03STGH030MSS

Article no longer available - archive entry

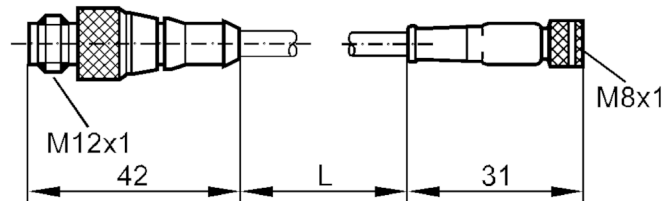

### Application

Special feature Halogen-free

### Electrical data

Operating voltage [V] 10...30 DC

Protection class III

### Operating conditions

Ambient temperature [°C] -25...90

Protection IP 67

### Mechanical data

Materials TPU

Material nut brass, nickel-plated / brass, nickel-plated

### Remarks

Pack quantity 1 pcs.

### Electrical connection - plug

Connector: 1 x M12, straight; Moulded body: TPU; Locking: brass, nickel-plated



# E10987




## Connection cable

VDOGF030MSS0002H03STGH030MSS

### Electrical connection


Cable: 2 m, PUR, Halogen-free, black, Ø 4.3 mm; 3 x 0.34 mm<sup>2</sup> (43 x Ø 0.1 mm )

### Connection

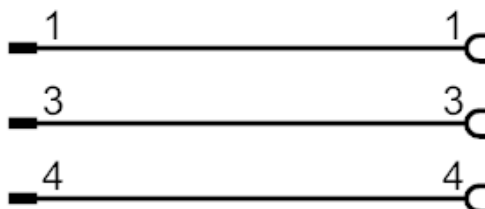

### Electrical connection - socket

 Connector: 1 x M8, straight; Moulded body: TPU; Locking: brass, nickel-plated



Article no longer available - archive entry