


Fibre optic diffuse reflection sensor

FT-00-P-V-E1/S 0,8m

Article no longer available - archive entry

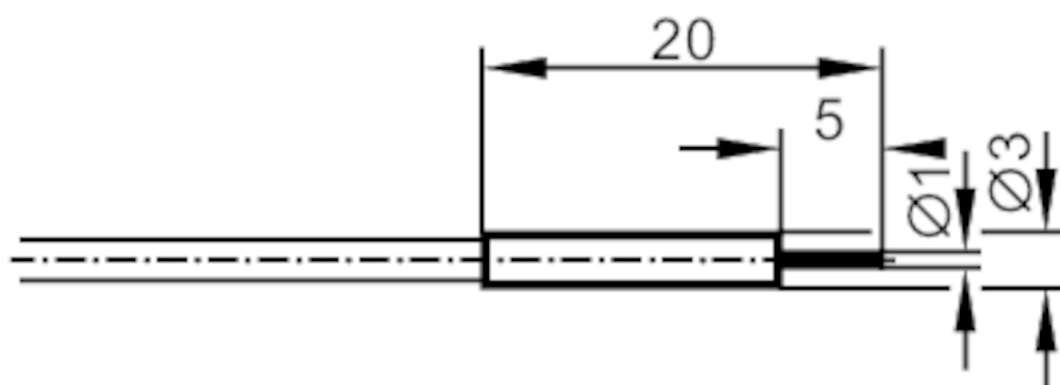

Application

Function principle	Diffuse reflection sensor
--------------------	---------------------------

Detection zone

Range with fibre optic amplifier type	OKF; OUF
---------------------------------------	----------

OKF

Range fibre optics [mm]	8
-------------------------	---

OUF

Range fibre optics [mm]	8
-------------------------	---

Operating conditions

Ambient temperature [°C]	-20...80
--------------------------	----------

Mechanical data

Version of sensing head	straight
-------------------------	----------

Sensing head diameter [mm]	1
----------------------------	---

Sensing head length [mm]	5
--------------------------	---

Total length [mm]	800
-------------------	-----

Min. bending radius [mm]	20
--------------------------	----

Materials	Adapter: PPE
-----------	--------------

Fibre material	glass
----------------	-------

E20096



Fibre optic diffuse reflection sensor

FT-00-P-V-E1/S 0,8m

Fibre head material	stainless steel (1.4305 / 303)
Fibre sheath material	PVC
Remarks	
Pack quantity	1 pcs.