


Fibre optic through-beam sensor

FE-00-A-A-E3/2M

Article no longer available - archive entry

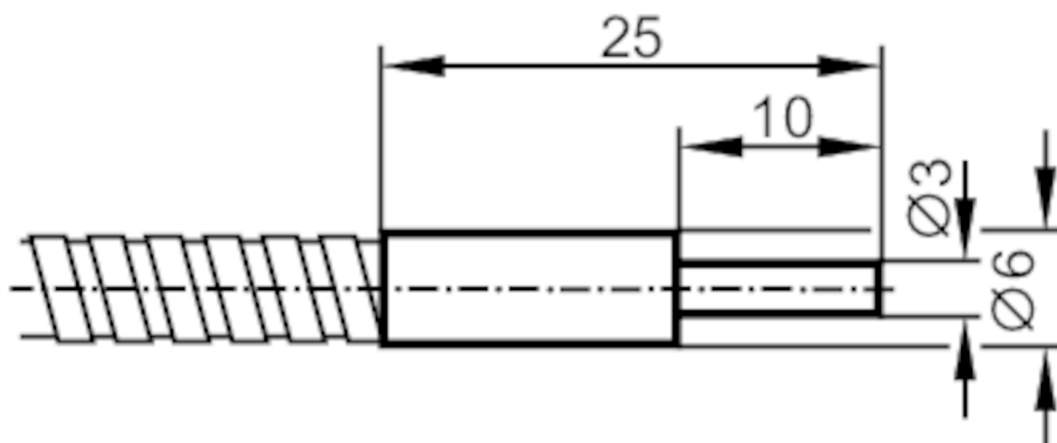

Application

Function principle

Through-beam sensor

Detection zone

Range with fibre-optic
amplifier type

OKF; OUF

OKF

Range of fibre optics

[mm]

96

OUF

Range of fibre optics

[mm]

96

Operating conditions

Ambient temperature

[°C]

-40...290

Mechanical data

Version of sensing head

straight

Sensing head diameter

[mm]

3

Sensing head length

[mm]

10

Total length

[mm]

2000

Min. bending radius

[mm]

20

Materials

Adapter: ABS

Fibre material

glass

E20268



Fibre optic through-beam sensor

FE-00-A-A-E3/2M

Fibre head material	aluminium
Fibre sheath material	aluminium
Remarks	
Pack quantity	1 pcs.