


# E43221



## Coaxial pipe for level sensors

## LR COAX TUBE NPT L1600

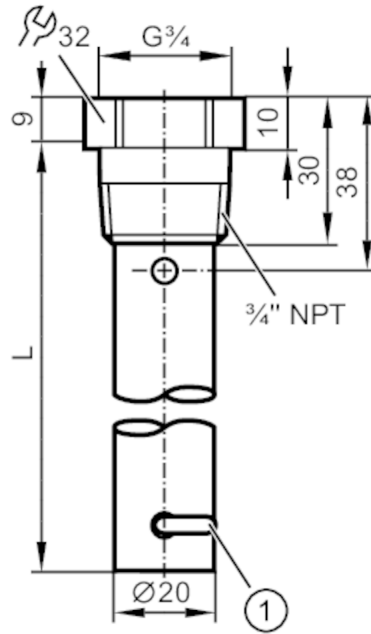

1 fixing bracket for centring piece

**CRN**

| Application                                    |                                                                                                                                    |
|------------------------------------------------|------------------------------------------------------------------------------------------------------------------------------------|
| Design                                         | for level sensors LR                                                                                                               |
| Medium temperature [°C]                        | -40...200                                                                                                                          |
| Pressure rating [bar]                          | 16                                                                                                                                 |
| Vacuum resistance [mbar]                       | -1000                                                                                                                              |
| MAWP (for applications according to CRN) [bar] | 16                                                                                                                                 |
| Mechanical data                                |                                                                                                                                    |
| Weight [g]                                     | 875                                                                                                                                |
| Materials                                      | Coaxial pipe: stainless steel (1.4301 / 304); Centring piece: PPS reinforced fibre; fixing bracket: stainless steel (1.4310 / 301) |
| Sensor connection                              | threaded connection G 3/4 internal thread                                                                                          |
| Process connection                             | threaded connection 3/4" NPT external thread                                                                                       |
| Length L [mm]                                  | 1600                                                                                                                               |
| Remarks                                        |                                                                                                                                    |
| Pack quantity                                  | 1 pcs.                                                                                                                             |