




EC2089

Steckersatz
für
CabinetModule
CR2016
konfektionierbar

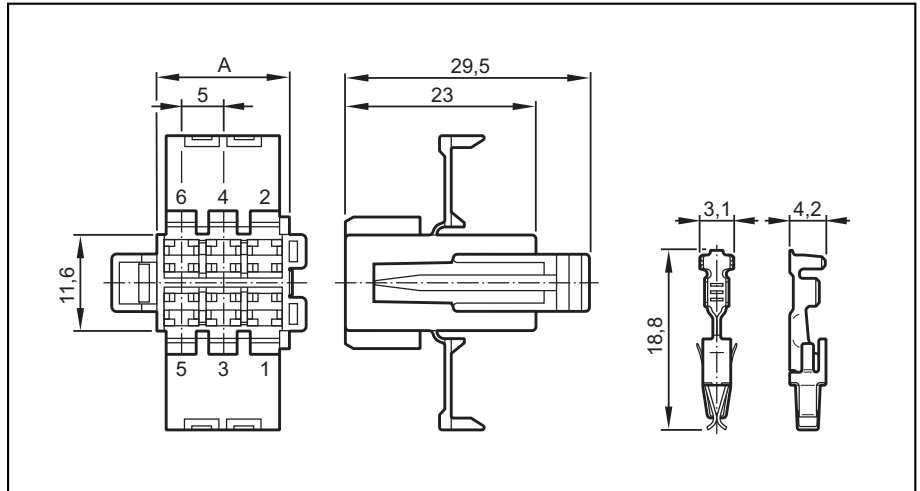

Technische Daten

**AMP Crimp-Buchsengehäuse
inkl. Crimp-Kontakte (Junior Power Timer)**

Lieferumfang

Gehäuse

Kontakte

Schutzart

Material (Gehäuse)


Material (Crimp-Kontakte)

1 x 6-polig, 2 x 14-polig, 2 x 18-polig
75

IP 20


PBT (schwarz)

 CuSn (verzinnt)




A = 11

 4-polig




A = 16

6-polig

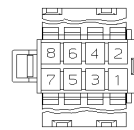


A = 21

8-polig

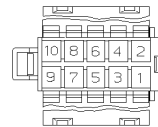


A = 26

10-polig

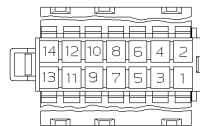


A = 36

14-polig

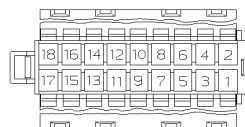

A = 46

18-polig

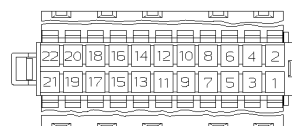


A = 56

22-polig



EC2089

Plug set
for
CabinetModule
CR2016
wirable

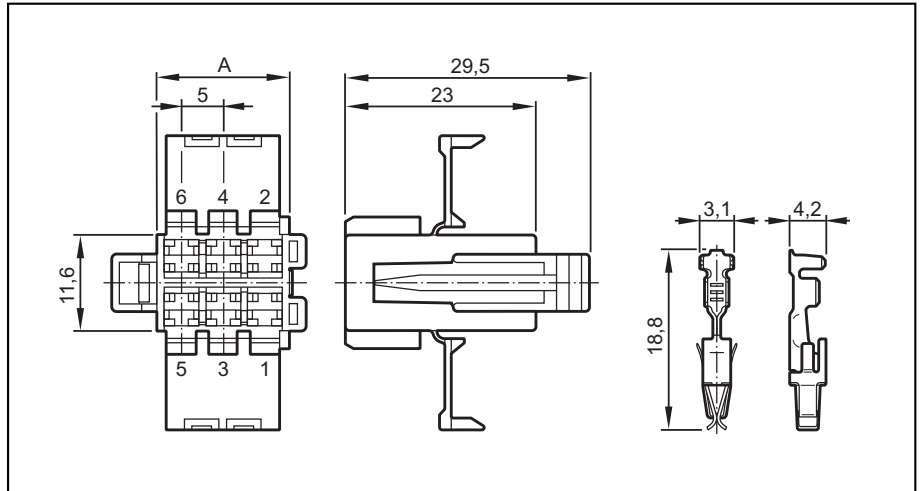

Technical data

Components
housing
contacts

Protection

Material (housing)

Material (contacts)


**AMP Crimp housing
incl. Crimp contacts (Junior Power Timer)**

1 x 6 pins, 2 x 14 pins, 2 x 18 pins
75

IP 20


PBT (black)

 CuSn (tin plated)




A = 11

 4 pins




A = 16

6 pins

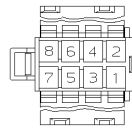


A = 21

8 pins

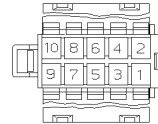


A = 26

10 pins

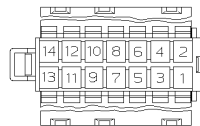


A = 36

14 pins

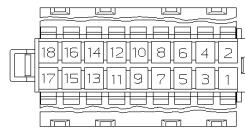

A = 46

18 pins

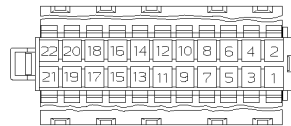

A = 56

22 pins