


CR1053



Programmable graphic display for controlling mobile machines

R360/PDM360/compact/MONO-E

Article no longer available - archive entry

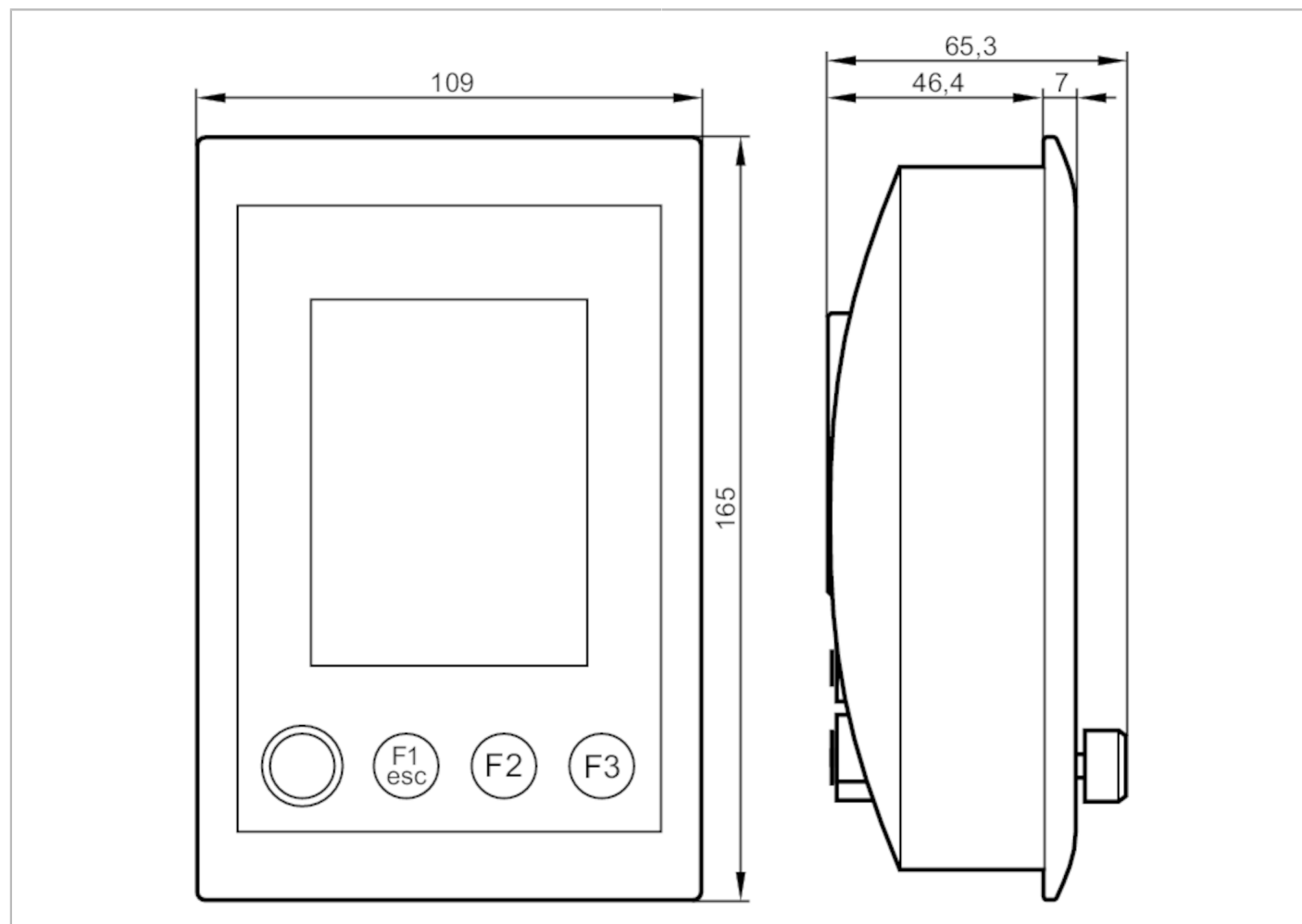

Electrical data

Operating voltage [V] 10...32 DC

Inputs / outputs

Number of inputs and outputs Number of digital inputs: 2; Number of digital outputs: 2

Inputs

Number of digital inputs 2

Outputs

Number of digital outputs 2

Software / programming

PLC function to IEC 61131-3 yes

Interfaces

Number of CAN interfaces 1

Number of Ethernet interfaces 1

Number of R232 interfaces 1

CR1053



Programmable graphic display for controlling mobile machines

R360/PDM360/compact/MONO-E

Mechanical data		
Weight	[g]	1447
Type of mounting		panel / surface
Dimensions	[mm]	165 x 109 x 65.3
Displays / operating elements		
Display		3,8" monochrome display
Operating elements	3	freely programmable backlit function keys
	1	encoder with pushbutton
Display resolution		320 x 240
Display type		monochrome display
Display size		3.8"
Display background illumination		LED
Data memories		
Real-time clock		yes
Remarks		
Pack quantity		1 pcs.
Electrical connection		
Connector: 1 x M12		