




Multifunction display for monitoring analogue standard signals

DISPLAY/AX360

discontinued article

replaced by: DX2041; discontinued article – Discontinuation date: 31.03.2017

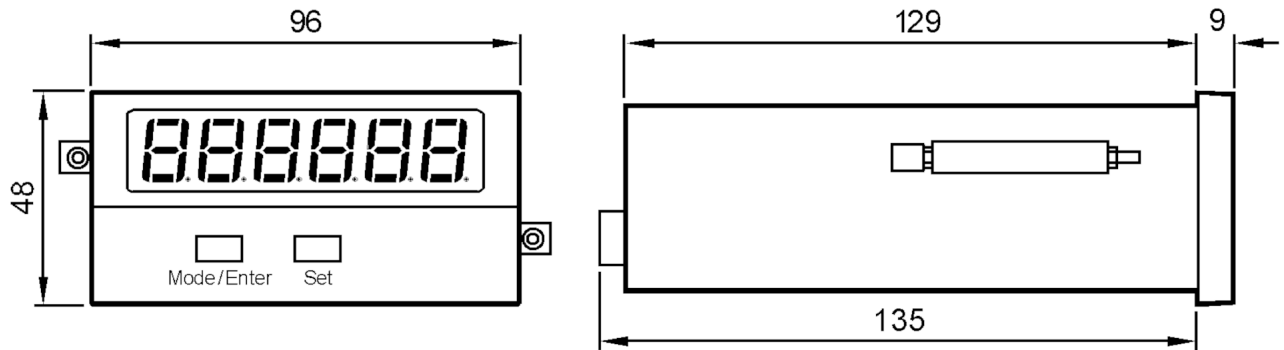

| Application | |
|-------------------------------------|--|
| Application | display of analogue standard signals; e.g. pressure sensors, temperature sensors or flow sensors |
| Electrical data | |
| Frequency AC [Hz] | 50...60 |
| Operating voltage tolerance [%] | 33...58 |
| Operating voltage [V] | 230 / 115 AC / 24 DC |
| Current consumption [mA] | 110 (18 V); 90 (24 V); 80 (30 V) |
| Auxiliary energy for sensors DC [V] | 24; ($\pm 15\%$, 150 mA; Short-circuit proof) |
| Inputs / outputs | |
| Number of inputs and outputs | Number of analogue inputs: 2 |
| Inputs | |
| Number of analogue inputs | 2 |
| Outputs | |
| Analogue current output [mA] | 4...20 |
| Analogue voltage output [V] | 0...10 |




Multifunction display for monitoring analogue standard signals

DISPLAY/AX360

| Operating conditions | | |
|--|---------|---|
| Ambient temperature | [°C] | 0...45 |
| Storage temperature | [°C] | -25...70 |
| Protection | | IP 65; (on the front) |
| Protection rating terminals | | IP 20 |
| Tests / approvals | | |
| EMC | | EN 50081-1 |
| | | EN 61000-6-2 |
| MTTF | [years] | 38 |
| Mechanical data | | |
| Weight | [g] | 552 |
| Materials | | Noryl UL94-V-0 |
| Displays / operating elements | | |
| Display | | 7-segment LED display, orange 6-digit 15 mm |
| Electrical connection | | |
| screw terminals, DC: 10 x ...1.5 mm ² | | |
| screw terminals, AC: 4 x ...2.5 mm ² | | |

Connection

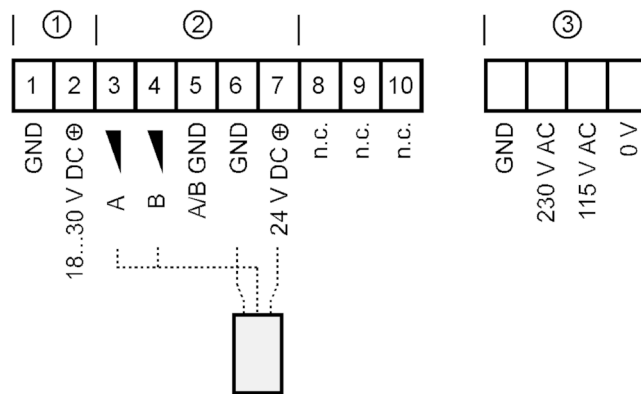

discontinued article

replaced by: DX2041; discontinued article – Discontinuation date: 31.03.2017