

E10659




Splitter box

ZDO8H059MSS0000-00STAM190MSS

Article no longer available - archive entry

Alternative articles: EBC012

When selecting an alternative article and accessories please note that technical data may differ!

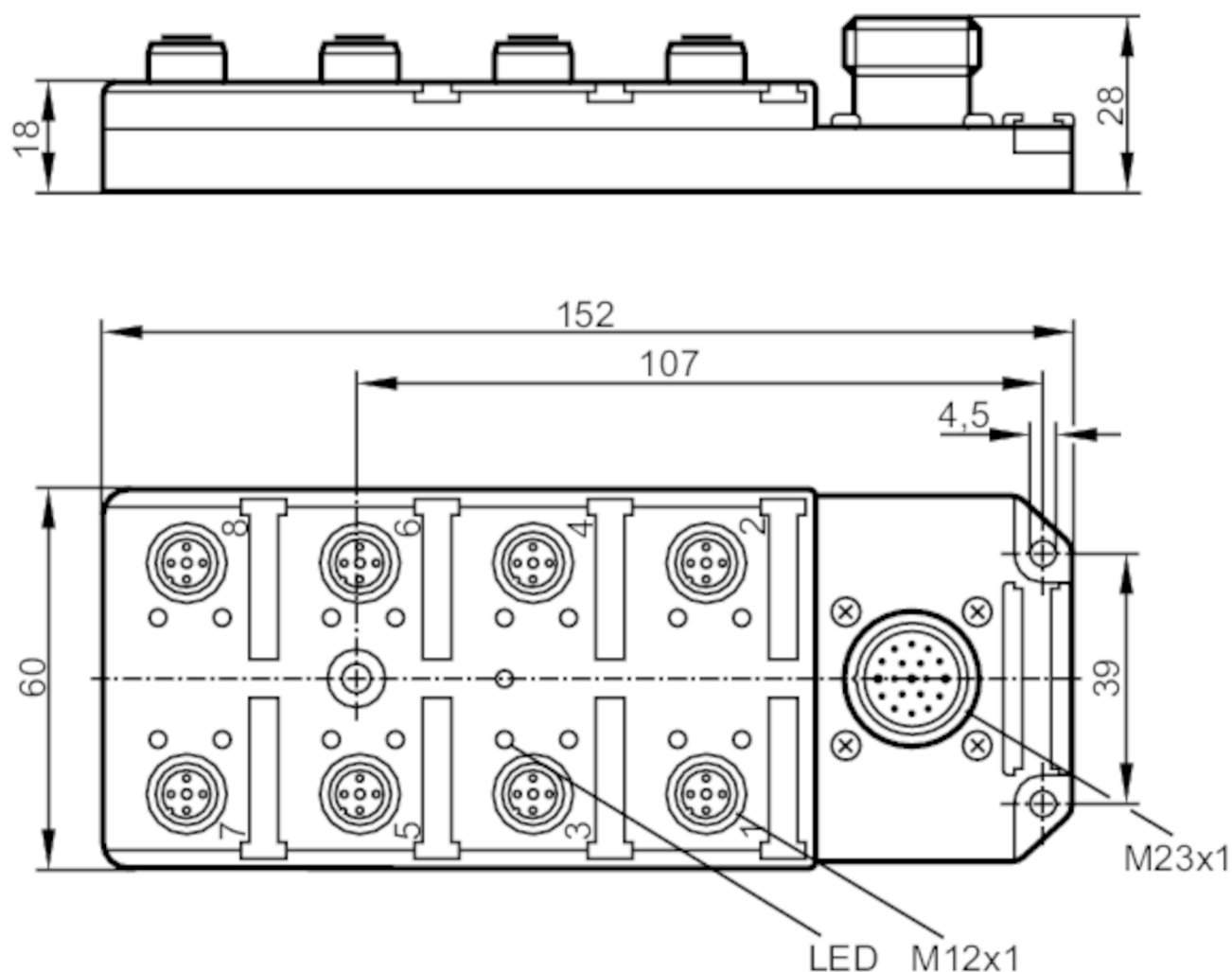

Application

Special feature	Free from silicone; Gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	10...30 DC
Protection class		II
Max. current load per module/slot	[A]	4
Max. current load total	[A]	10

Operating conditions

Ambient temperature	[°C]	-15...80
Protection		IP 67

E10659



Splitter box

ZDO8H059MSS0000-00STAM190MSS


Mechanical data		
Dimensions	[mm]	28 x 60 x 152
Materials		TPU
Moulded-body material		TPU
Number of ports splitter box		8
Connector type		M12

Displays / operating elements		
Display	switching status	16 x LED, yellow
	operation	1 x LED, green

Remarks	
Pack quantity	1 pcs.

Electrical connection - Connection

Connector: 1 x M23; Moulded body: TPU; Contacts: gold-plated; Tightening torque: 0.5 Nm

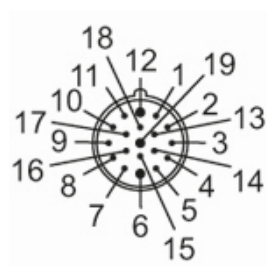


E10659



Splitter box

ZDO8H059MSS0000-00STAM190MSS

Connection

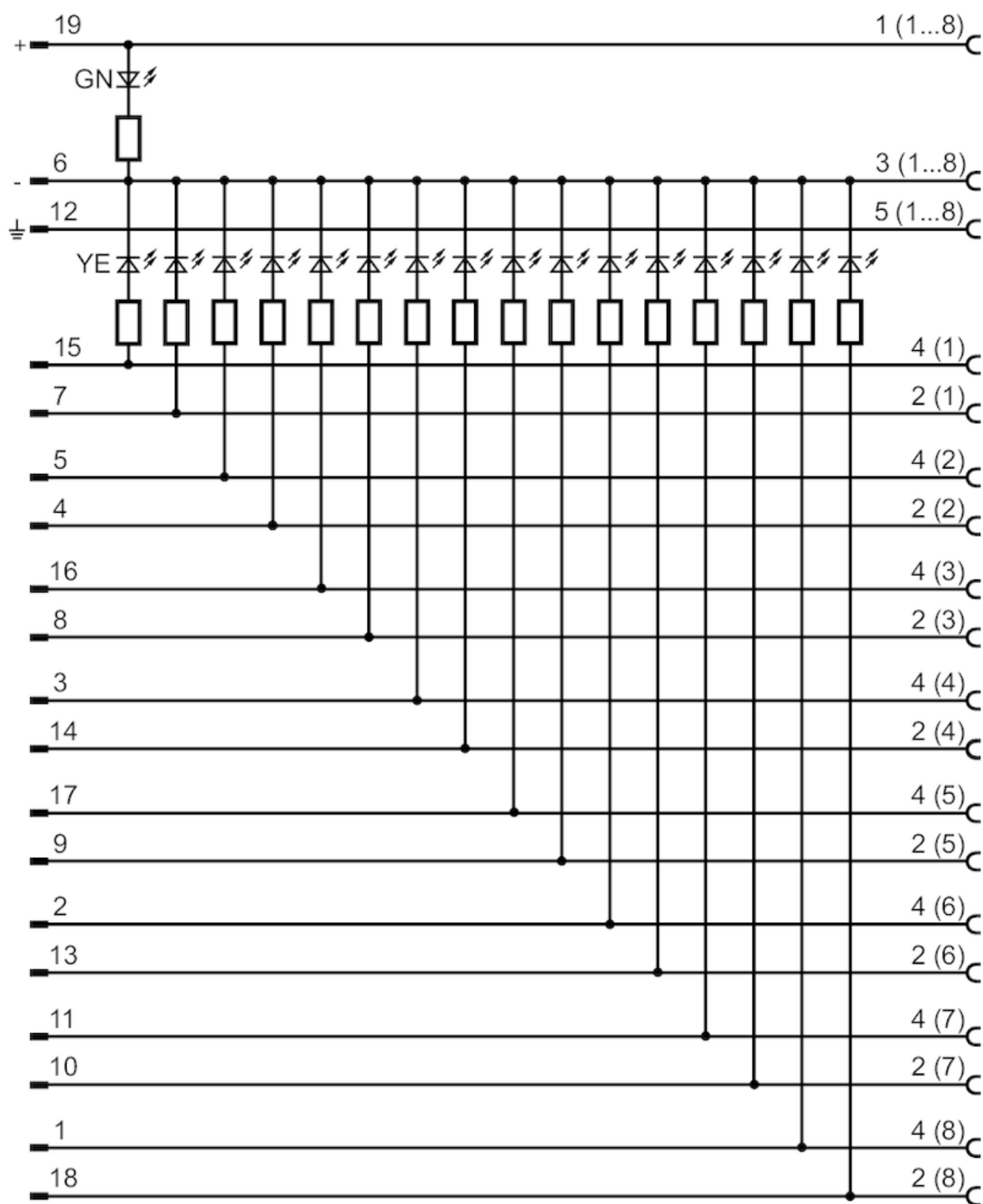

E10659



Splitter box

ZDO8H059MSS0000-00STAM190MSS

Electrical connection - slot

Connector: 8 x M12; coding: A; Moulded body: TPU; Contacts: gold-plated; Tightening torque: 0.5 Nm

