

E10718




Connecting cable with socket

ADOAH042VAS0005A04

Article no longer available - archive entry

Alternative articles: EVC008
When selecting an alternative article and accessories please note that technical data may differ!

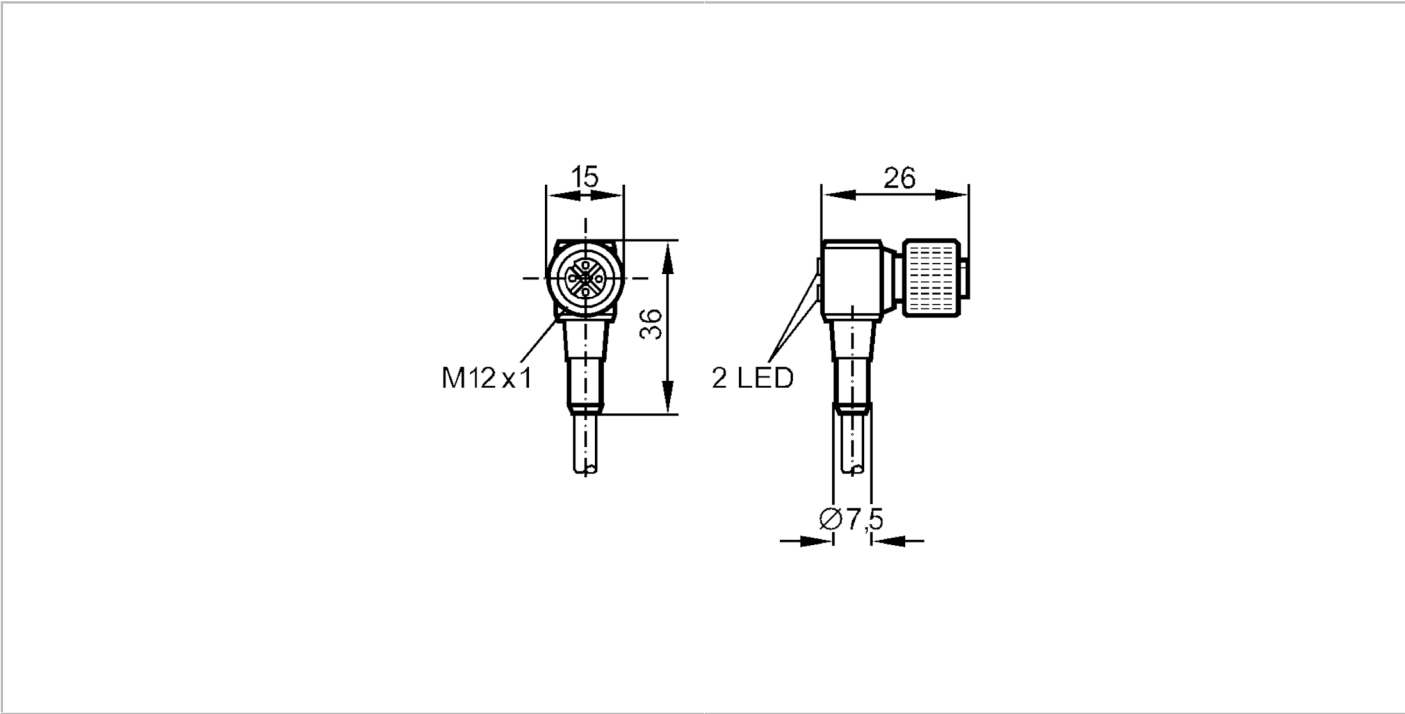

Electrical data		
Operating voltage	[V]	10...30 DC
Outputs		
Electrical design		PNP
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 68
Mechanical data		
Dimensions	[mm]	36 x 15 x 26
Materials		PUR
Moulded-body material		PUR
Material nut		stainless steel (303/1.4305)
Displays / operating elements		
Display	switching status	1 x LED, yellow
	operation	1 x LED, green
Remarks		
Pack quantity		1 pcs.

E10718



Connecting cable with socket

ADOAH042VAS0005A04

Electrical connection


Cable: 5 m, PUR / PVC, black, Ø 4.5 mm; 4 x 0.34 mm² (182 x Ø 0.05 mm)

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: PUR; Locking: stainless steel (303/1.4305)



Connection

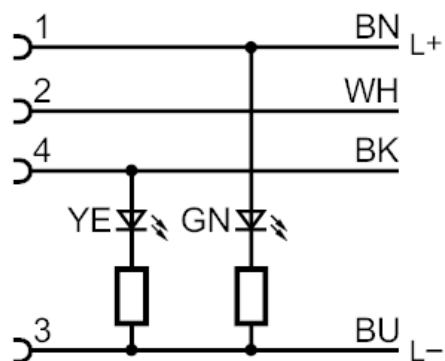

BK =	Core colours :
BN =	black
BU =	brown
WH =	blue
	white