


E10851



Connecting cable with socket

ADOAA030VAS0005E03

Article no longer available - archive entry

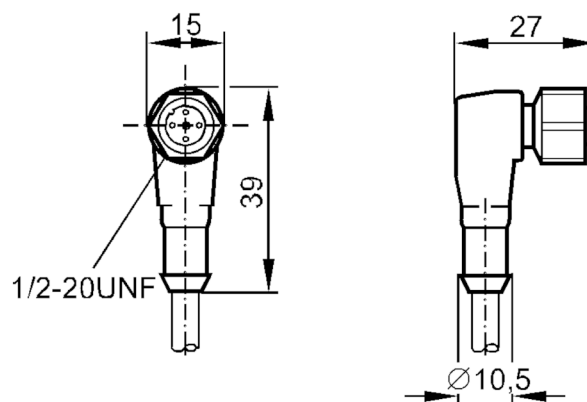

Application

Special feature	Free from silicone; Gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 250 AC
-------------------	-----	----------

Operating conditions

Ambient temperature	[°C]	-25...70
Protection		IP 67

Mechanical data

Dimensions	[mm]	27 x 15 x 39
Materials		PVC
Moulded-body material		PVC
Material nut		stainless steel (316L/1.4404)

Remarks

Pack quantity	1 pcs.
---------------	--------

E10851



Connecting cable with socket

ADOAA030VAS0005E03

Electrical connection


Cable: 5 m, PVC, yellow, Ø 5 mm; 3 x 0.34 mm² (19 x Ø 0.16 mm)

Electrical connection - socket

Connector: 1 x 1/2", angled; coding: C; Moulded body: PVC; Locking: stainless steel (316L/1.4404); Contacts: gold-plated



Connection

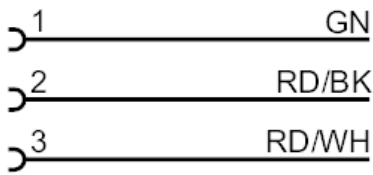

GN =
RD/BK =
RD/WH =

Core colours :
green
red/black
red/white