


E10874



Connection cable

VDOAH043MSS00,6I04STGH040MSS

Article no longer available - archive entry

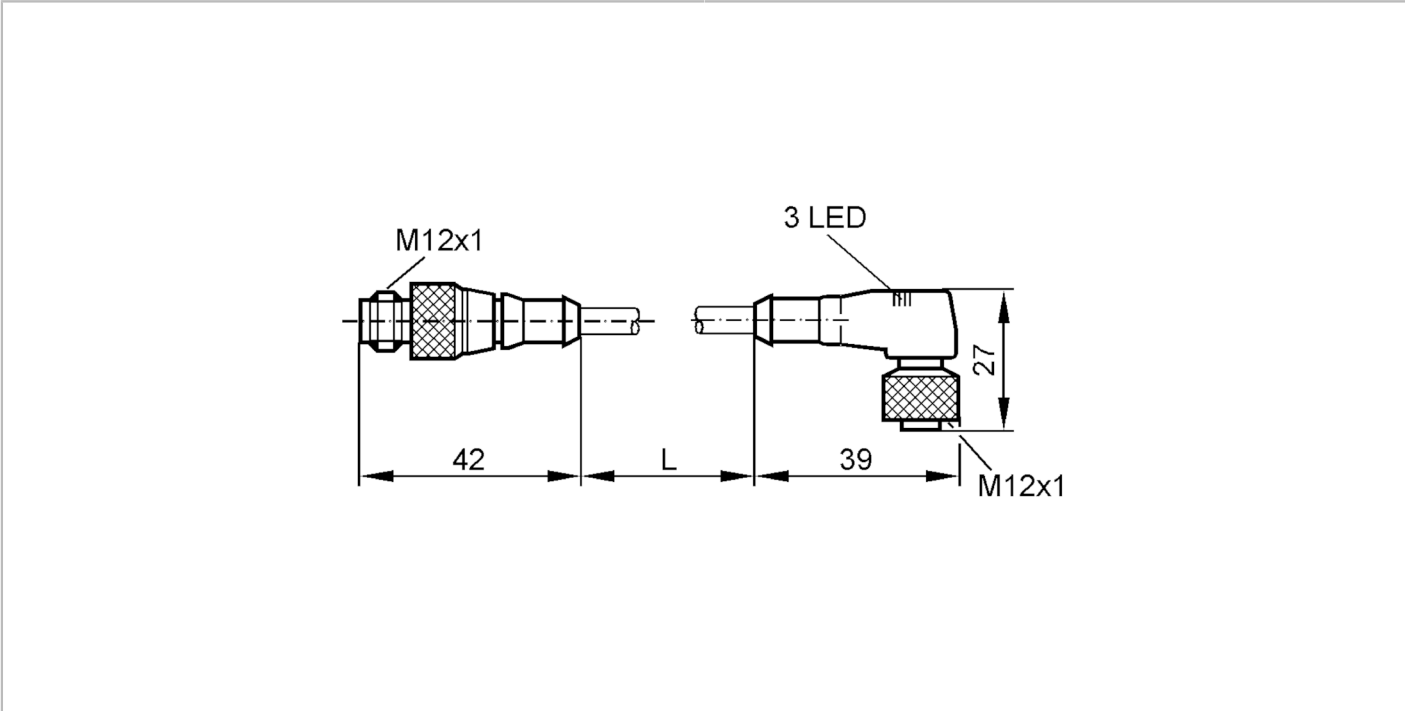

Application		
Special feature	Halogen-free	
Electrical data		
Operating voltage	[V]	10...30 DC
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection	IP 67	
Mechanical data		
Materials	TPU	
Moulded-body material	TPU	
Material nut	brass, nickel-plated	
Displays / operating elements		
Display	switching status	2 x LED, yellow
	operation	1 x LED, green
Remarks		
Pack quantity	1 pcs.	

E10874



Connection cable

VDOAH043MSS00,6I04STGH040MSS

Electrical connection - plug


Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated; Tightening torque: 0.5 Nm



Electrical connection

Cable: 0.6 m, PUR, Halogen-free; cross-linked; 4 x 0.34 mm² (19 x Ø 0.15 mm)

Connection

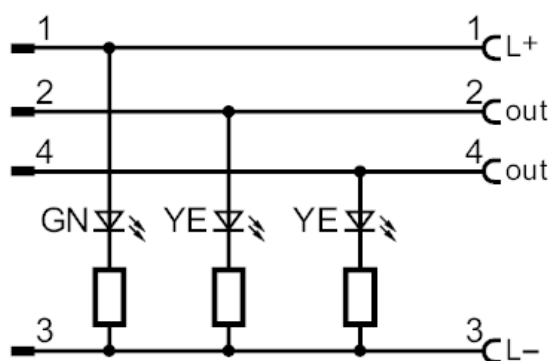

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU; Locking: brass, nickel-plated; Tightening torque: 0.5 Nm

