


Connecting cable with socket

ADOGK120MSS0010A

Article no longer available - archive entry

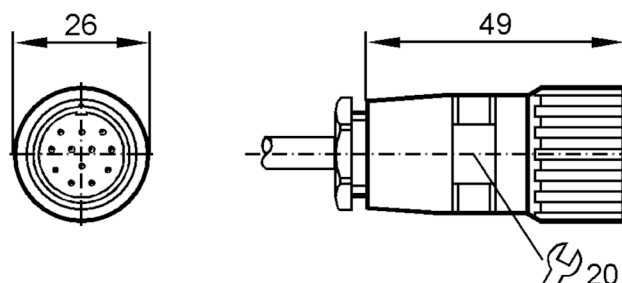

Electrical data

Operating voltage	[V]	10...30 DC
-------------------	-----	------------

Operating conditions

Ambient temperature	[°C]	-25...90
---------------------	------	----------

Protection	IP 65
------------	-------

Mechanical data

Dimensions	[mm]	26 x 26 x 49
------------	------	--------------

Materials	brass nickel-plated
-----------	---------------------

Moulded-body material	brass, nickel-plated
-----------------------	----------------------

Material nut	brass, nickel-plated
--------------	----------------------

Remarks


Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 10 m, PUR; 12 x 1.0 mm² (128 x Ø 0.1 mm)

Electrical connection - socket

Connector: 1 x M23, straight; Moulded body: brass, nickel-plated; Locking: brass, nickel-plated

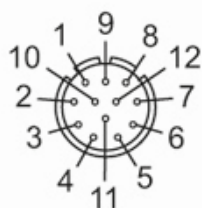

E10896



Connecting cable with socket

ADOGK120MSS0010A

Connection

1	BK 1
2	BK 2
3	BK 3
4	BK 4
5	BK 5
6	BK 6
7	BK 7
8	BK 8
9	BK 9
10	BK 10
11	BK 11
12	GN/YE