


# E10930



## Connection cable

VDOGF030MSS0002H03STGF030MSS

Article no longer available - archive entry

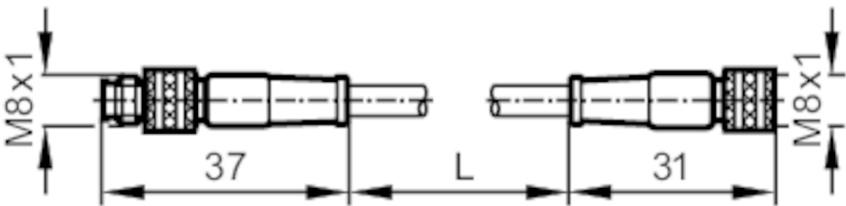

| Application                  |                      |
|------------------------------|----------------------|
| Special feature              | Halogen-free         |
| Electrical data              |                      |
| Operating voltage [V]        | 10...55 DC           |
| Protection class             | III                  |
| Operating conditions         |                      |
| Ambient temperature [°C]     | -25...90             |
| Protection                   | IP 67                |
| Mechanical data              |                      |
| Materials                    | TPU                  |
| Moulded-body material        | TPU                  |
| Material nut                 | brass, nickel-plated |
| Remarks                      |                      |
| Pack quantity                | 1 pcs.               |
| Electrical connection - plug |                      |

Connector: 1 x M8, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated



# E10930




## Connection cable

VDOGF030MSS0002H03STGF030MSS

### Electrical connection

Cable: 2 m, Halogen-free; 3 x 0.34 mm<sup>2</sup>

### Connection

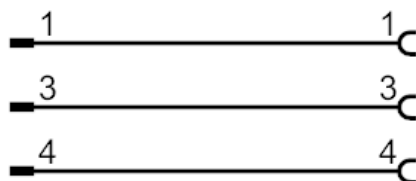

### Electrical connection - socket

Connector: 1 x M8, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated

