


E10952



Connection cable

VDOGH040MSS0005H04STGH040MSS

Article no longer available - archive entry

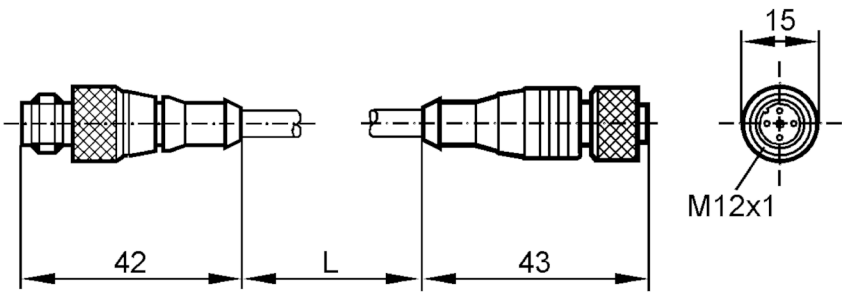

Application		
Special feature		Halogen-free
Electrical data		
Operating voltage	[V]	< 250 AC / < 300 DC
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Dimensions	[mm]	15 x 15 x 42
Materials		TPU
Moulded-body material		TPU
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated



E10952



Connection cable

VDOGH040MSS0005H04STGH040MSS

Electrical connection

Cable: 5 m, PUR, Halogen-free; 4 x 0.34 mm²

Connection



Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated

