

# E10293




## Connecting cable with socket

ADOGH040MSS0002F03

Article no longer available - archive entry

replaced by: E10915

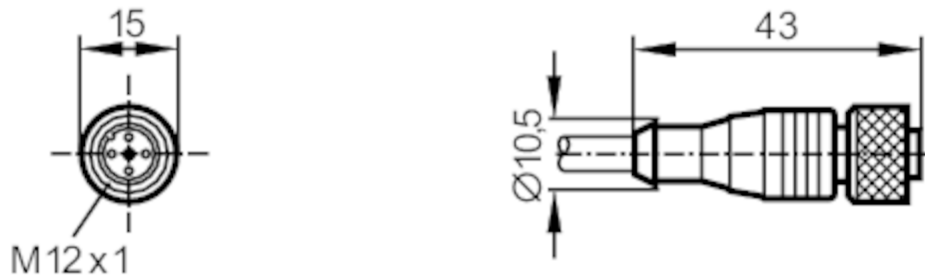

### Electrical data

Operating voltage [V] < 250 AC / < 300 DC

### Operating conditions

Ambient temperature [°C] -25...90

Protection IP 67

### Mechanical data

Dimensions [mm] 15 x 15 x 43

Materials TPU

Material nut brass, anti-spatter

### Remarks

 
Pack quantity 1 pcs.

### Electrical connection

Cable: 2 m, PVC, orange, Ø 5 mm; cross-linked; 3 x 0.34 mm<sup>2</sup> (19 x Ø 0.15 mm)

### Electrical connection - socket

Connector: 1 x M12, straight; Moulded body: TPU; Locking: brass, anti-spatter; Tightening torque: 0.5 Nm




# E10293



## Connecting cable with socket

ADOGH040MSS0002F03

### Connection

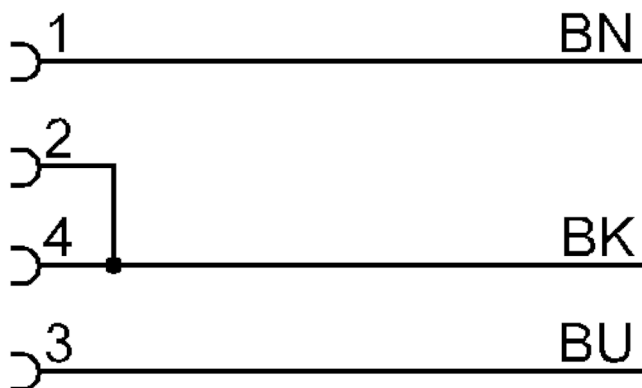

Core colours :

BN = brown  
BK = black  
BU = blue

Article no longer available - archive entry

replaced by: E10915