

E11719




Splitter box

ZDO4H050MSS0000-00STAK120MSS

Article no longer available - archive entry

Alternative articles: EBC001
When selecting an alternative article and accessories please note that technical data may differ!

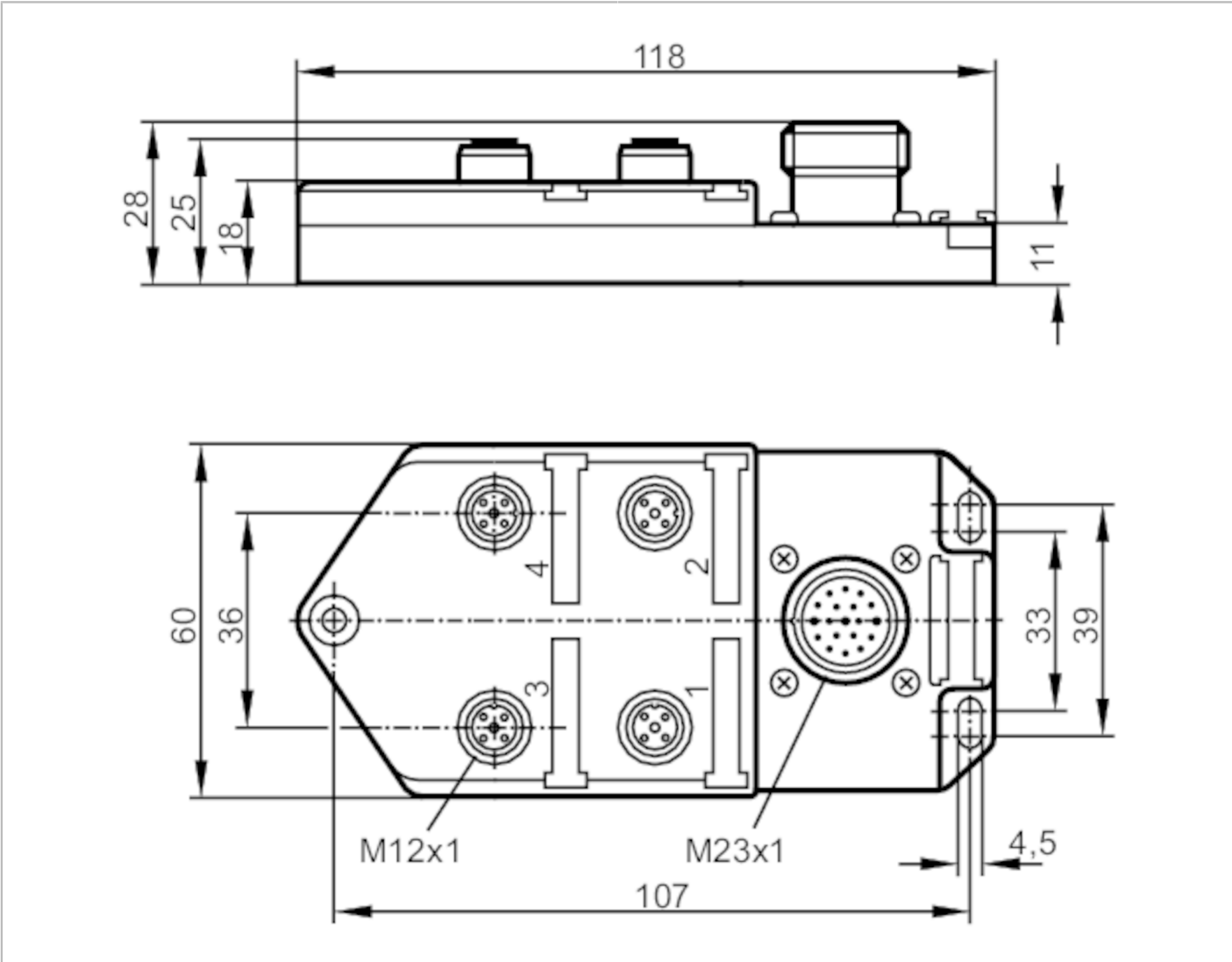

Application		
Special feature		Free from silicone; Gold-plated contacts
Free from silicone		yes
Electrical data		
Operating voltage	[V]	< 60 AC / < 75 DC
Protection class		II
Max. current load per module/slot	[A]	4
Max. current load total	[A]	12
Operating conditions		
Ambient temperature	[°C]	-15...80
Protection		IP 67

E11719



Splitter box

ZDO4H050MSS0000-00STAK120MSS

Mechanical data		
Dimensions	[mm]	28 x 60 x 118
Materials		TPU
Moulded-body material		TPU
Number of ports splitter box		4
Connector type		M12


Remarks	
Pack quantity	1 pcs.

Electrical connection - Connection

Connector: 1 x M23; Moulded body: TPU; Contacts: gold-plated; Tightening torque: 0.5 Nm



Connection

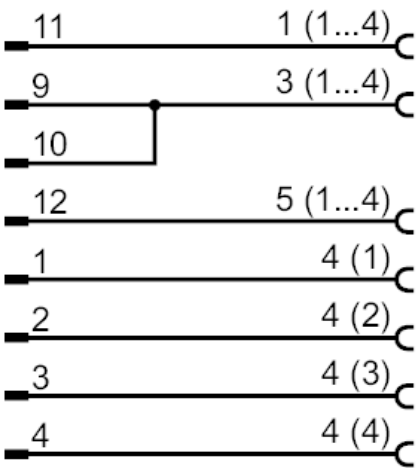

E11719



Splitter box

ZDO4H050MSS0000-00STAK120MSS

Electrical connection - slot

Connector: 4 x M12; coding: A; Moulded body: TPU; Contacts: gold-plated; Tightening torque: 0.5 Nm

