


# E11211



## Connection cable

VDOGF040MSS0002H04STGH040MSS

Article no longer available - archive entry

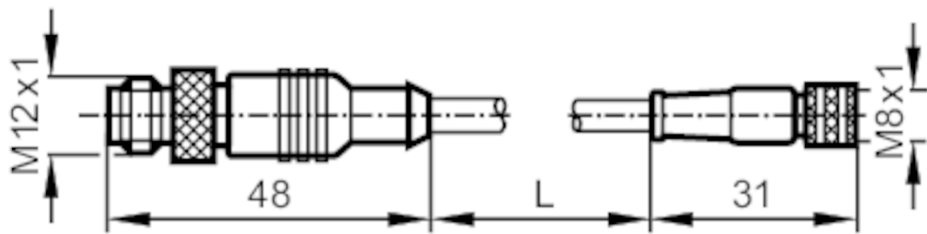

| Application                 |                                                        |
|-----------------------------|--------------------------------------------------------|
| Special feature             | Free from silicone; Halogen-free; Gold-plated contacts |
| Free from silicone          | yes                                                    |
| Electrical data             |                                                        |
| Operating voltage [V]       | < 60 AC / < 75 DC                                      |
| Protection class            | III                                                    |
| Max. current load total [A] | 3                                                      |
| Operating conditions        |                                                        |
| Ambient temperature [°C]    | -25...85                                               |
| Protection                  | IP 68                                                  |
| Mechanical data             |                                                        |
| Materials                   | PUR                                                    |
| Moulded-body material       | PUR                                                    |
| Material nut                | brass, nickel-plated                                   |
| Remarks                     |                                                        |
| Pack quantity               | 1 pcs.                                                 |

# E11211



## Connection cable

VDOGF040MSS0002H04STGH040MSS

### Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm



### Electrical connection

Cable: 2 m, PUR, Halogen-free, black, Ø 4.4 mm; 4 x 0.25 mm<sup>2</sup> (32 x Ø 0.1 mm )

### Connection



### Electrical connection - socket

Connector: 1 x M8, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.6...0.7 Nm

