


E12408



Adapter socket

EDOGH050MSS00,5E05 (M16)

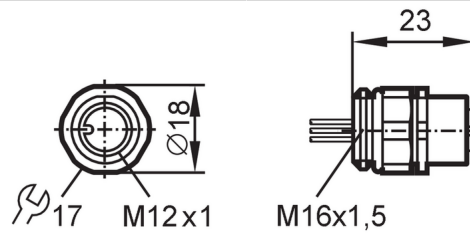

Application	
Application	Industrial applications / factory automation
Electrical data	
Operating voltage [V]	< 125 AC/DC
Operating conditions	
Ambient temperature [°C]	-25...85
Protection	IP 68
Mechanical data	
Weight [g]	23.6
Mounting thread	M16
Materials	housing: diecast zinc nickel-plated
Accessories	
Items supplied	nut: 1 x M16
Remarks	
Pack quantity	1 pcs.
Electrical connection	
Cable: 0.5 m, PVC; 5 x 0.25 mm ²	
Electrical connection - socket	
Connector: 1 x M12, straight; coding: A; Contacts: 5	


E12408



Adapter socket

EDOGH050MSS00,5E05 (M16)

Connection

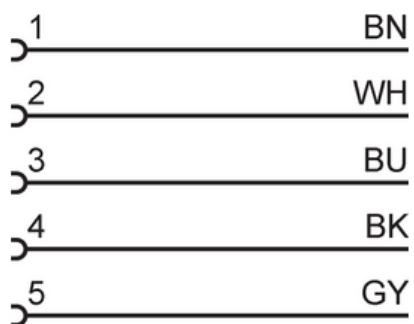

Core colours :
BK = black
BN = brown
BU = blue
GY = grey
WH = white