


# E12538



## Damping magnet

MAGNET M6.1 NEODYM, DRILL HOLE

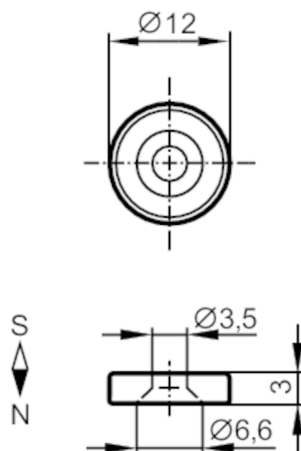

### Operating conditions

|                     |      |          |
|---------------------|------|----------|
| Ambient temperature | [°C] | -40...80 |
|---------------------|------|----------|

### Mechanical data

|                         |      |              |
|-------------------------|------|--------------|
| Weight                  | [g]  | 3            |
| Dimensions              | [mm] | Ø 12 / L = 3 |
| Materials               |      | neodymium    |
| Magnetic field strength | [mT] | 250          |

### Remarks

|               |        |
|---------------|--------|
| Pack quantity | 1 pcs. |
|---------------|--------|