


## Connecting cable with socket

ADOGH050MSS0060C05

Article no longer available - archive entry

Alternative articles: EVC591

When selecting an alternative article and accessories please note that technical data may differ!

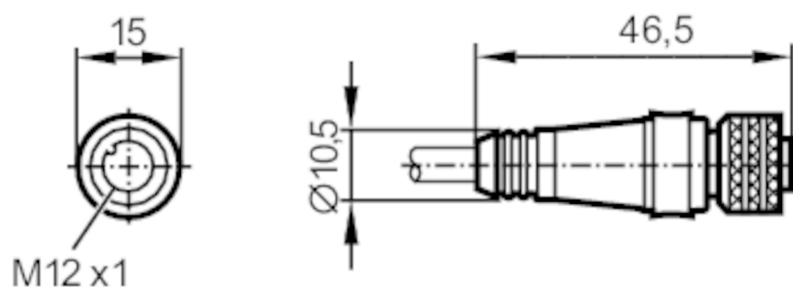

## Application

Special feature	Free from silicone; Halogen-free; Gold-plated contacts; Screened cable
Free from silicone	yes

## Electrical data

Operating voltage	[V]	< 30 AC / < 36 DC
Protection class		III
Max. current load total	[A]	4

## Operating conditions

Ambient temperature	[°C]	-25...80
Protection		IP 67

## Mechanical data

Weight	[g]	2577.6
Dimensions	[mm]	15 x 15 x 46.5
Materials		TPU
Moulded-body material		TPU
Material nut		brass, nickel-plated

## Remarks

Pack quantity	1 pcs.
---------------	--------

# E12236



## Connecting cable with socket


ADOGH050MSS0060C05

### Electrical connection


Cable: 60 m, PUR, Halogen-free, black, Ø 5.5 mm, shielded; 5 x 0.25 mm<sup>2</sup> (32 x Ø 0.1 mm )

### Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.5 Nm; Shielded connection cable: screen not connected

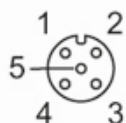

### Connection

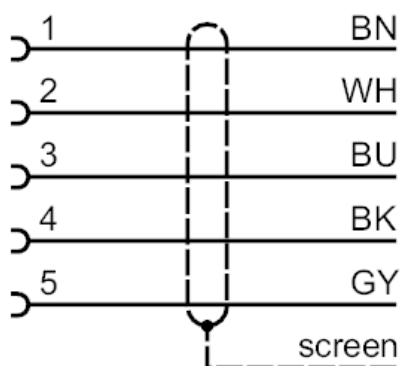

	Core colours :
BK =	black
BN =	brown
BU =	blue
GY =	grey
WH =	white