




Connecting cable with socket

ADOAH040MSC0002X04

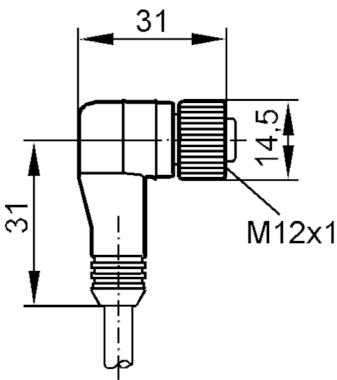

Application	
Special feature	Gold-plated contacts
Electrical data	
Operating voltage [V]	< 300 AC/DC
Operating conditions	
Ambient temperature [°C]	-45...105
Protection	IP 68
Mechanical data	
Weight [g]	158.757
Materials	TPE
Moulded-body material	TPE
Material nut	zinc, PTFE coated
Remarks	
Pack quantity	1 pcs.
Electrical connection	
Cable: 2 m, yellow; 4 x 0.75 mm² / AWG 18	
Electrical connection - socket	
Connector: 1 x M12, angled; coding: A; Moulded body: TPE; Locking: zinc, PTFE coated; Contacts: gold-plated	

E18405



Connecting cable with socket

ADOAH040MSC0002X04

Connection



	Core colours :
BK =	black
BN =	brown
BU =	blue
WH =	white