




Connecting cable with socket

ADOAH040MSC0010X04

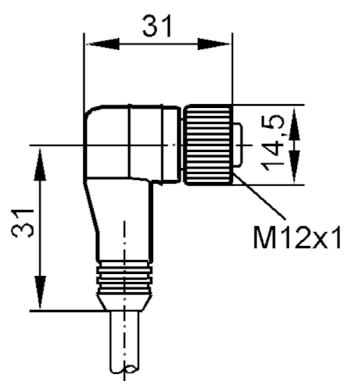

Application

Special feature

Gold-plated contacts

Electrical data

Operating voltage

[V]

< 300 AC/DC

Operating conditions

Ambient temperature

[°C]

-45...105

Protection

IP 68

Mechanical data

Weight

[g]

771.106

Materials

TPE

Moulded-body material

TPE

Material nut

zinc, PTFE coated

Remarks

Pack quantity

1 pcs.

Electrical connection

Cable: 10 m, yellow; 4 x 0.75 mm² / AWG 18

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPE; Locking: zinc, PTFE coated; Contacts: gold-plated




E18407



Connecting cable with socket

ADOAH040MSC0010X04

Connection

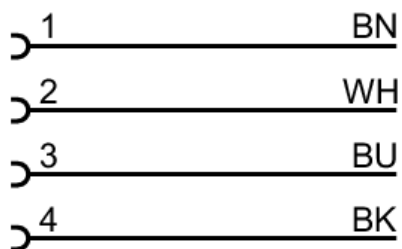

	Core colours :
BK =	black
BN =	brown
BU =	blue
WH =	white