


E18410



Connection cable

VDOGH040MSC0001X04STGH040MSC

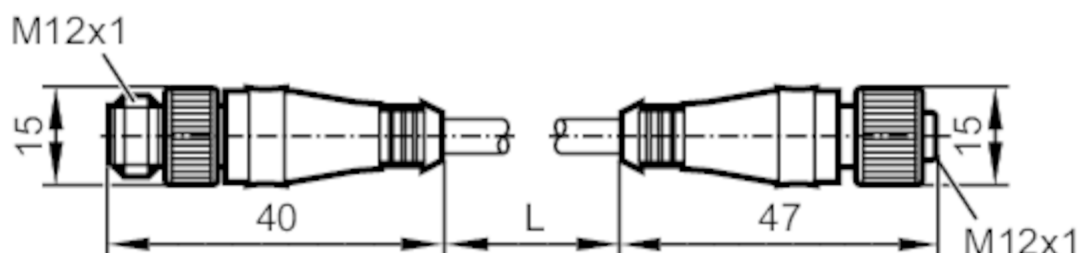

Application

Special feature	Free from silicone; Gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 250 AC/DC
-------------------	-----	-------------

Operating conditions

Ambient temperature	[°C]	-45...105
Protection		IP 68

Mechanical data

Weight	[g]	90.718
Dimensions	[mm]	15 x 15 x 40
Materials		TPE yellow
Moulded-body material		TPE
Material nut		zinc, PTFE coated

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPE; Locking: zinc, PTFE coated; Contacts: gold-plated



E18410



Connection cable

VDOGH040MSC0001X04STGH040MSC

Electrical connection

Cable: 1 m, yellow; 4 x 0.75 mm² / AWG 18

Connection



Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPE; Locking: zinc, PTFE coated; Contacts: gold-plated

