


# E18411



## Connection cable

VDOGH040MSC0002X04STGH040MSC

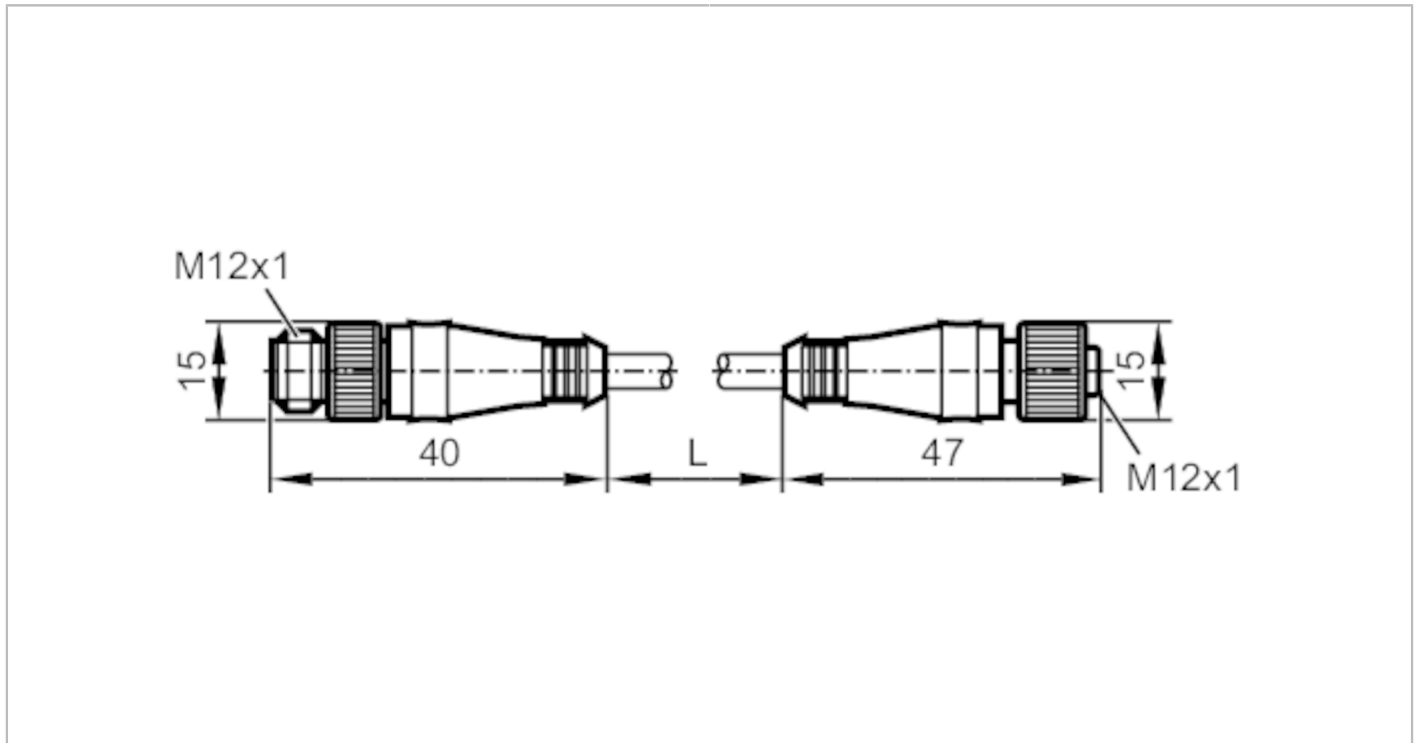

Application	
Special feature	Free from silicone; Gold-plated contacts
Free from silicone	yes
Electrical data	
Operating voltage [V]	< 250 AC/DC
Operating conditions	
Ambient temperature [°C]	-45...105
Protection	IP 68
Mechanical data	
Weight [g]	181.437
Dimensions [mm]	15 x 15 x 40
Materials	TPE yellow
Moulded-body material	TPE / TPE
Material nut	zinc, PTFE coated / zinc, PTFE coated
Remarks	
Pack quantity	1 pcs.

### Electrical connection - plug

Connector: 1 x M12, straight; Moulded body: TPE; Locking: zinc, PTFE coated; Contacts: gold-plated



# E18411




## Connection cable

VDOGH040MSC0002X04STGH040MSC

### Electrical connection

Cable: 2 m, yellow; 4 x 0.75 mm<sup>2</sup> / AWG 18

### Connection

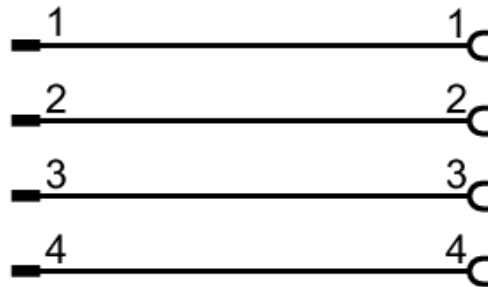

### Electrical connection - socket

Connector: 1 x M12, straight; Moulded body: TPE; Locking: zinc, PTFE coated; Contacts: gold-plated

