


E18518



Connecting cable with socket

ADOGH040ZDS0010H04

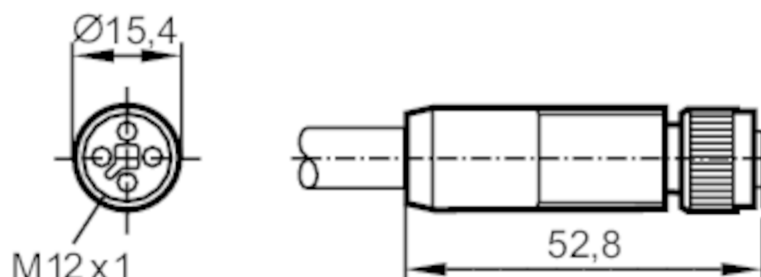

Application

Special feature	Gold-plated contacts
Design	power cable, T-coded

Electrical data

Operating voltage	[V]	< 60 AC
Max. current load total	[A]	12

Operating conditions

Ambient temperature	[°C]	-25...85
Protection		IP 67

Mechanical data

Weight	[g]	1061.405
Dimensions	[mm]	15.4 x 15.4 x 52.8
Materials		TPU
Moulded-body material		TPU
Material nut		diecast zinc, nickel-plated

Remarks

Pack quantity		1 pcs.
---------------	--	--------

E18518



Connecting cable with socket


ADOGH040ZDS0010H04

Electrical connection


Cable: 10 m, PUR, black, Ø 8 mm; 4 x 1.5 mm²

Electrical connection - socket

Connector: 1 x M12, straight; coding: T; Moulded body: TPU; Locking: diecast zinc, nickel-plated; Contacts: gold-plated

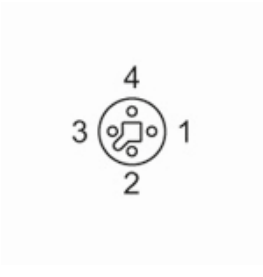

Connection

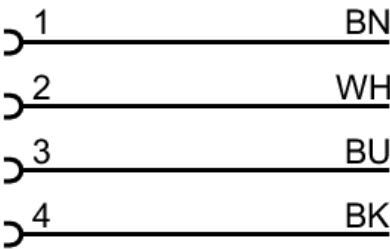

BK =	Core colours :
BN =	black
BU =	brown
WH =	blue
	white