


E18014



Connecting cable with socket

ADOGH040VAS0005E04

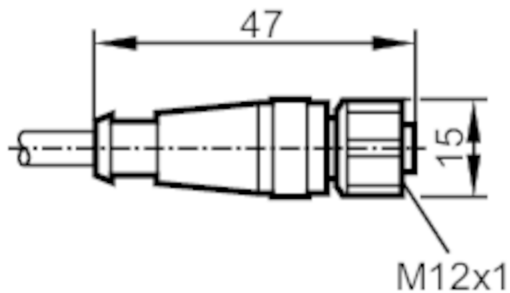

Application		
Special feature		Gold-plated contacts
Electrical data		
Operating voltage	[V]	< 300 AC/DC
Operating conditions		
Ambient temperature	[°C]	-10...100
Protection		IP 68
Mechanical data		
Weight	[g]	181.437
Dimensions	[mm]	15 x 15 x 47
Materials		PVC
Moulded-body material		PVC
Material nut		stainless steel (316Ti/1.4571)
Remarks		
Pack quantity		1 pcs.

E18014



Connecting cable with socket

ADOGH040VAS0005E04

Electrical connection

Cable: 5 m, PVC, black, Ø 5 mm; 4 x 0.34 mm² / AWG 22

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: PVC; Locking: stainless steel (316Ti/1.4571); Contacts: gold-plated



Connection



	Core colours :
BK =	black
BN =	brown
BU =	blue
WH =	white