


# E18015



## Connecting cable with socket

ADOGH040VAS0010E04 - BLACK

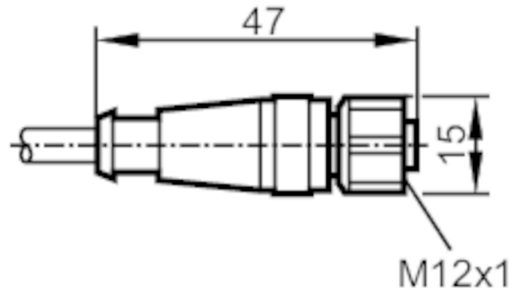

### Application

Special feature Gold-plated contacts

### Electrical data

Operating voltage [V] < 300 AC/DC

### Operating conditions

Ambient temperature [°C] -10...100

Protection IP 68

### Mechanical data

Weight [g] 362.874

Dimensions [mm] 15 x 15 x 47

Materials PVC

Moulded-body material PVC

Material nut stainless steel (1.4571/316Ti)

### Remarks

Pack quantity 1 pcs.

### Electrical connection

Cable: 10 m, PVC, black; 4 x 0.34 mm<sup>2</sup> / AWG 22

### Electrical connection - socket

 
Connector: 1 x M12, straight; Moulded body: PVC; Locking: stainless steel (1.4571/316Ti); Contacts: gold-plated

# E18015




## Connecting cable with socket

ADOGH040VAS0010E04 - BLACK



### Connection

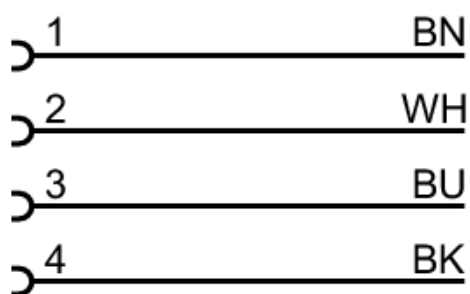

Core colours :

BK = black  
BN = brown  
BU = blue  
WH = white