


Connecting cable with socket

ADOAA050MSS0004A05

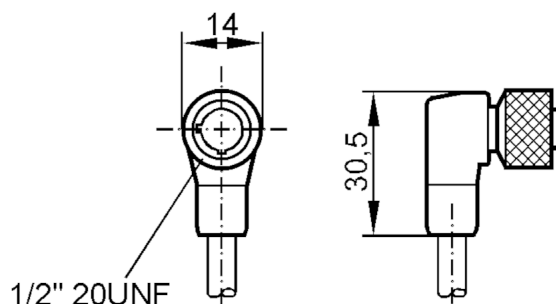

Electrical data

Operating voltage	[V]	< 250 AC/DC
Max. current load total	[A]	4

Operating conditions

Ambient temperature	[°C]	-40...90
Protection		IP 68

Mechanical data

Weight	[g]	181.437
Materials		TPU
Moulded-body material		TPU
Material nut		brass, nickel-plated

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 4 m, PUR, black, Ø 5.3 mm; 5 x 0.34 mm² (19 x Ø 0.16 mm) / AWG 22

Electrical connection - socket

Connector: 1 x 1/2", angled; coding: C; Moulded body: TPU; Locking: brass, nickel-plated




E18027



Connecting cable with socket

AD0AA050MSS0004A05

Connection

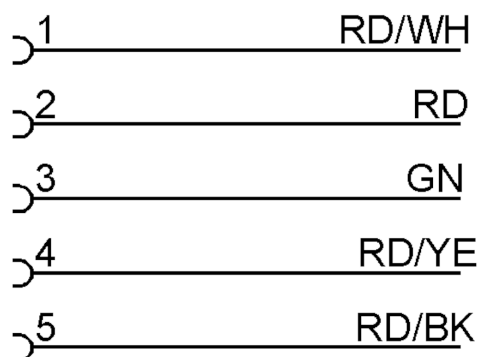

	Core colours :
BK =	black
GN =	green
RD =	red
WH =	white
YE =	yellow