


E18031



Wirable socket

SDOGH040MSSFKPG

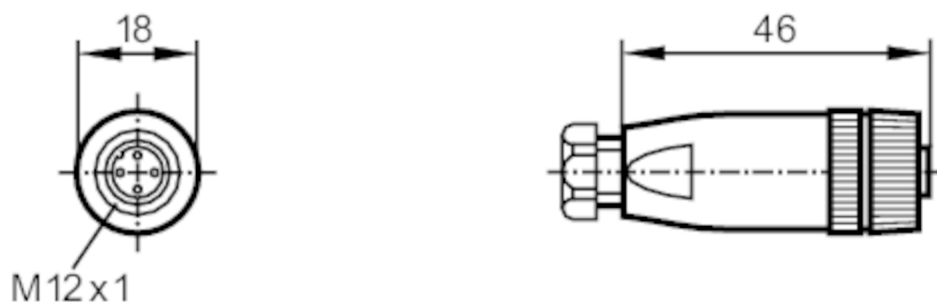

Application

Special feature

Gold-plated contacts

Electrical data

Operating voltage [V] < 250 AC/DC

Max. current load total [A] 4; (...40 °C)

Operating conditions

Ambient temperature [°C] -25...90

Protection IP 67

Mechanical data

Weight [g] 27.216

Dimensions [mm] 18 x 18 x 46

Materials PA

Moulded-body material PA

Material nut ZnAl / Ni

Remarks

Pack quantity 1 pcs.

E18031



Wirable socket

SDOGH040MSSFKPG

Electrical connection

terminals: ...0.75 mm²; Cable sheath: Ø 8...10 mm

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: PA; Locking: ZnAl / Ni; Contacts: gold-plated



Connection

