


E18046



Connecting cable with socket

AD0GB030VAS0002E03

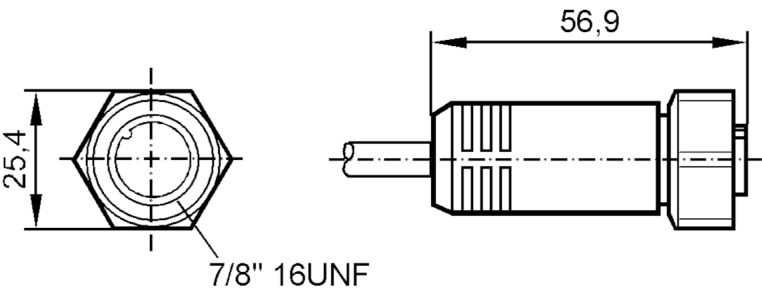

Application		
Special feature		Gold-plated contacts
Electrical data		
Operating voltage	[V]	< 300 AC/DC
Operating conditions		
Ambient temperature	[°C]	-20...105
Protection		IP 68
Mechanical data		
Weight	[g]	199.58
Materials		PVC
Moulded-body material		PVC
Material nut		stainless steel (316L/1.4404)
Remarks		
Pack quantity		1 pcs.

E18046



Connecting cable with socket

ADOGB030VAS0002E03

Electrical connection


Cable: 2 m, PVC, grey; 3 x 0.75 mm² / AWG 18

Electrical connection - socket

Connector: 1 x 7/8", straight; coding: A; Moulded body: PVC; Locking: stainless steel (316L/1.4404); Contacts: gold-plated



Connection

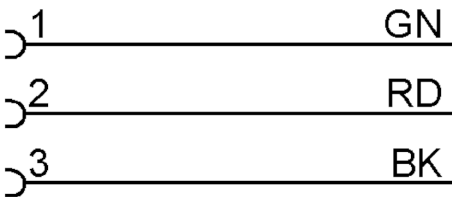

BK = Core colours :
GN = black
RD = green
 red