


E18048



Connecting cable with socket

ADOGB030VAS0006E03

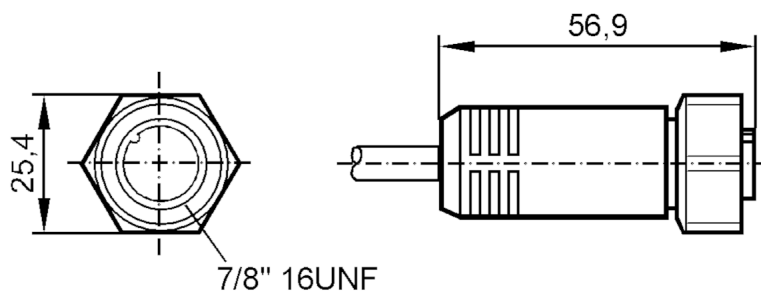

Application

Special feature	Gold-plated contacts
-----------------	----------------------

Electrical data

Operating voltage	[V]	< 300 AC/DC
-------------------	-----	-------------

Operating conditions

Ambient temperature	[°C]	-20...105
Protection		IP 68

Mechanical data

Weight	[g]	580.598
Materials		PVC
Moulded-body material		PVC
Material nut		stainless steel (316L/1.4404)

Remarks

Pack quantity	1 pcs.
---------------	--------

E18048



Connecting cable with socket

ADOGB030VAS0006E03

Electrical connection


Cable: 6 m, PVC, grey; 3 x 0.75 mm² / AWG 18

Electrical connection - socket

Connector: 1 x 7/8", straight; coding: A; Moulded body: PVC; Locking: stainless steel (316L/1.4404); Contacts: gold-plated



Connection

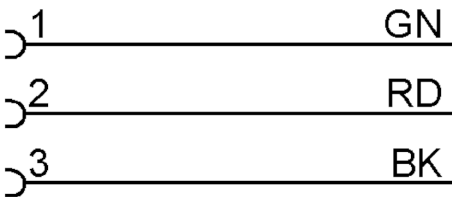

BK = Core colours :
GN = black
RD = green
 red