




Wirable plug

SSTA040MSSFKPG

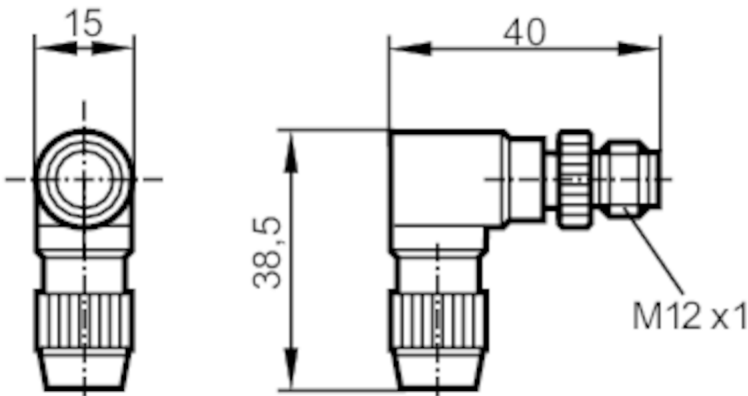

Electrical data		
Operating voltage	[V]	< 250 DC
Max. current load total	[A]	3
Operating conditions		
Ambient temperature	[°C]	-25...85
Protection		IP 68
Mechanical data		
Weight	[g]	22.68
Dimensions	[mm]	38.5 x 15 x 40
Materials		PA 6.6
Moulded-body material		PA 6.6
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.
Electrical connection		
insulation displacement technology: 0.14...0.34 mm²; Core insulation: PVC / PETP; (Ø 1.0...1.55 mm); Cable sheath: Ø 4...5 mm		
Electrical connection - plug		
Connector: 1 x M12, angled; coding: A; Moulded body: PA 6.6; Locking: brass, nickel-plated		

E18060



Wirable plug

SSTA040MSSFKPG

Connection

