




Connecting cable with socket

ADOGB050VAS0010E05

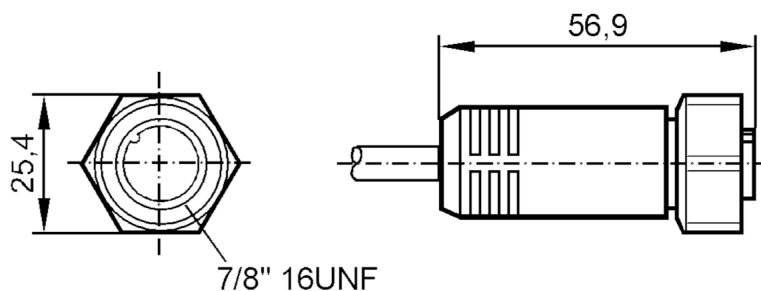

Application		
Special feature		Gold-plated contacts
Electrical data		
Operating voltage	[V]	< 300 AC/DC
Operating conditions		
Ambient temperature	[°C]	-20...105
Protection		IP 68
Mechanical data		
Weight	[g]	1292.737
Materials		PVC
Moulded-body material		PVC
Material nut		stainless steel (1.4404 / 316L)
Remarks		
Pack quantity		1 pcs.

E18098



Connecting cable with socket

ADOGB050VAS0010E05

Electrical connection


Cable: 10 m, PVC, grey; 5 x 0.75 mm² / AWG 18

Electrical connection - socket

Connector: 1 x 7/8", straight; coding: A; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated



Connection

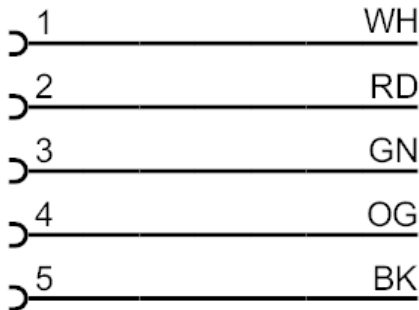

Core colours :
BK = black
GN = green
RD = red
OG = orange
WH = white