


Jumper cable with valve plug

VVDAC031MSS00,3H03STGH030MSS

Article no longer available - archive entry

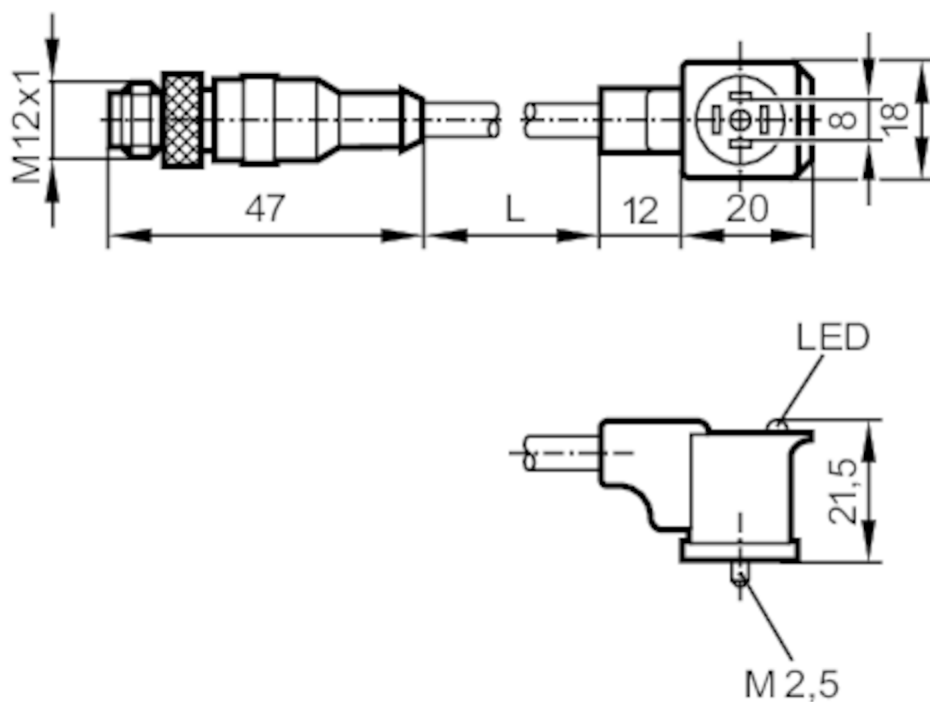

Application

Special feature	Free from silicone; Halogen-free; Gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 24 AC/DC
Overvoltage protection		yes; (VDR)
Max. current load total	[A]	3

Operating conditions

Ambient temperature	[°C]	-25...80
Protection		IP 65

Mechanical data

Weight	[g]	50.802
Materials		PUR
Moulded-body material		PUR
Material nut		brass, nickel-plated

Displays / operating elements

Display	operation	1 x LED, yellow
---------	-----------	-----------------

Accessories

Items supplied	screw
	panel for labelling

E18125



Jumper cable with valve plug

VVDAC031MSS00,3H03STGH030MSS

Remarks

Pack quantity

 
1 pcs.

Electrical connection

Cable: 0.3 m, PUR, Halogen-free, grey, Ø 5 mm; 3 x 0.5 mm² (42 x Ø 0.1 mm)


Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm



Electrical connection

Connection

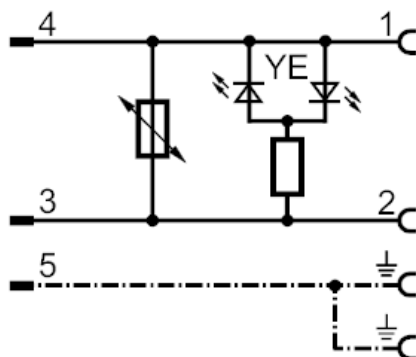

Electrical connection - socket

Connector: 1 x valve type C DIN, angled; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: nickel-plated brass; Tightening torque: 0.7...0.9 Nm

