



E18161

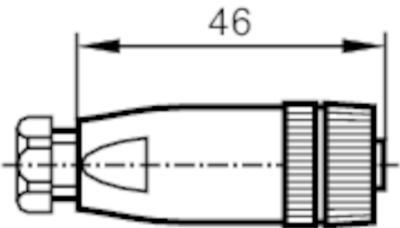

Wirable socket

SDOGH040VASFKPG9

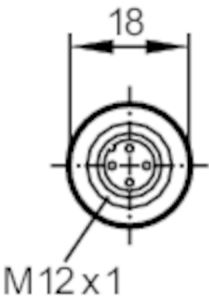

Electrical data

Operating voltage	[V]	< 250 AC / < 300 DC
Max. current load total	[A]	4

Operating conditions

Ambient temperature	[°C]	-40...85
Protection		IP 68

Mechanical data

Weight	[g]	27.216
Dimensions	[mm]	18 x 18 x 46
Materials		PA
Moulded-body material		PA
Material nut		stainless steel (316Ti/1.4571)

Remarks


Pack quantity	1 pcs.
---------------	--------

Electrical connection

terminals: ...0.75 mm²; Cable sheath: Ø 6...8 mm

Electrical connection - socket

 Connector: 1 x M12, straight; coding: A; Moulded body: PA; Locking: stainless steel (316Ti/1.4571); Contacts: pre-coppered brass



E18161

Wirable socket

SDOGH040VASFKPG9



Connection

