


E18165



Wirable socket

SDOGH080MSSFKPG

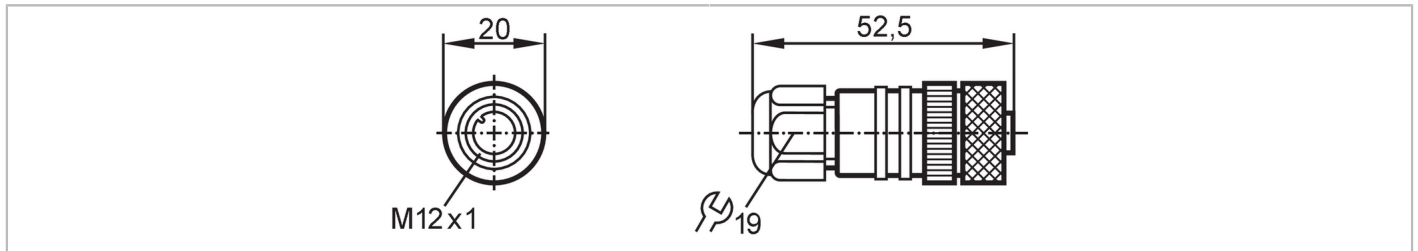

Application

Special feature	Free from silicone; Gold-plated contacts
Application	Industrial applications / factory automation
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 125 AC/DC
Max. current load total	[A]	4; (...40 °C)

Operating conditions

Ambient temperature	[°C]	-25...100
Protection		IP 68

Mechanical data

Weight	[g]	45.4
Dimensions	[mm]	20 x 20 x 52.5
Moulded-body material		PA
Material nut		brass, nickel-plated

Remarks


Pack quantity		1 pcs.
---------------	--	--------

Electrical connection

terminals: ...0.75 mm²; Cable sheath: Ø 6...8 mm

Electrical connection - socket

 Connector: 1 x M12, straight; coding: A; Contacts: 8, gold-plated; Moulded body: PA; Locking: brass, nickel-plated



E18165



Wirable socket

SDOGH080MSSFKPG

Connection

