


E18202



Connecting cable with socket

ADOGA030MSS0010X03

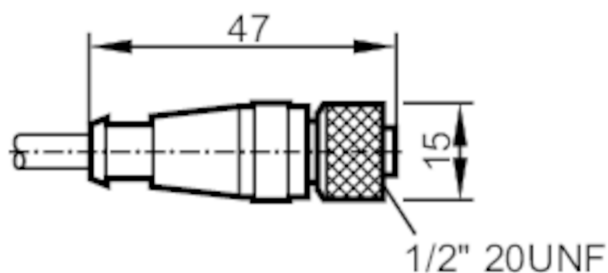

Application

Special feature	Gold-plated contacts
-----------------	----------------------

Electrical data

Operating voltage	[V]	< 300 AC/DC
-------------------	-----	-------------

Operating conditions

Ambient temperature	[°C]	-45...105
Protection		IP 68

Mechanical data

Weight	[g]	453.592
Dimensions	[mm]	15 x 15 x 47
Materials		TPE
Moulded-body material		TPE
Material nut		brass, nickel-plated

Remarks

Pack quantity	1 pcs.
---------------	--------

E18202



Connecting cable with socket

ADOGA030MSS0010X03

Electrical connection


Cable: 10 m, TPE-S, yellow; 3 x 0.34 mm² / AWG 22

Electrical connection - socket

Connector: 1 x 1/2", straight; coding: C; Moulded body: TPE; Locking: brass, nickel-plated; Contacts: gold-plated



Connection

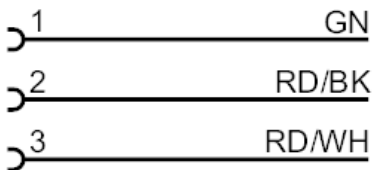

GN =	Core colours :
RD/BK =	green
RD/WH =	red/black
	red/white