


E18205



Connecting cable with socket

ADOAA030MSS0010X03

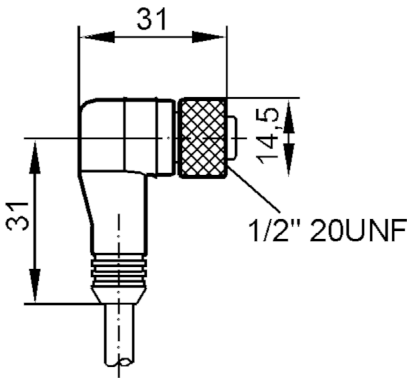

Application		
Special feature		Gold-plated contacts
Electrical data		
Operating voltage	[V]	< 300 AC/DC
Operating conditions		
Ambient temperature	[°C]	-45...105
Protection		IP 68
Mechanical data		
Weight	[g]	361.966
Dimensions	[mm]	31 x 14.5 x 31
Materials		TPE
Moulded-body material		TPE
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.

E18205



Connecting cable with socket

ADOAA030MSS0010X03

Electrical connection


Cable: 10 m, TPE-S, yellow; 3 x 0.34 mm² / AWG 22

Electrical connection - socket

Connector: 1 x 1/2", angled; coding: C; Moulded body: TPE; Locking: brass, nickel-plated; Contacts: gold-plated



Connection

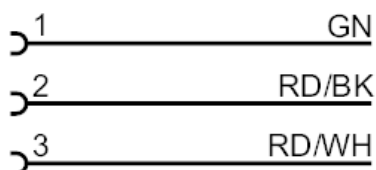

GN =	Core colours :
RD/BK =	green
RD/WH =	red/black
	red/white