


E18206



Connecting cable with socket

ADOGA030VAS0005E03

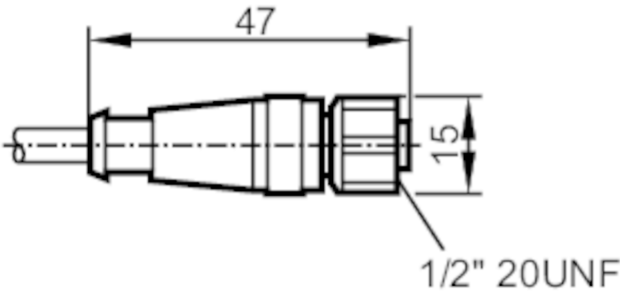

Application		
Special feature		Gold-plated contacts
Electrical data		
Operating voltage	[V]	< 300 AC/DC
Operating conditions		
Ambient temperature	[°C]	-10...100
Protection		IP 68
Mechanical data		
Weight	[g]	199.58
Dimensions	[mm]	15 x 15 x 47
Materials		PVC
Moulded-body material		PVC
Material nut		stainless steel (316Ti/1.4571)
Remarks		
Pack quantity		1 pcs.

E18206



Connecting cable with socket

ADOGA030VAS0005E03

Electrical connection


Cable: 5 m, PVC, yellow; 3 x 0.34 mm² / AWG 22

Electrical connection - socket

Connector: 1 x 1/2", straight; coding: C; Moulded body: PVC; Locking: stainless steel (316Ti/1.4571); Contacts: gold-plated



Connection

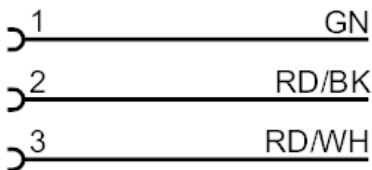

GN =	Core colours :
RD/BK =	green
RD/WH =	red/black
	red/white