


E18242



Connecting cable with socket

ADOGA050MSS0010A05

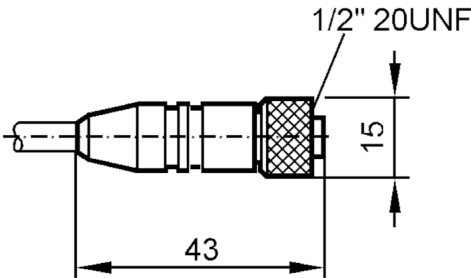

Electrical data		
Operating voltage	[V]	< 250 AC/DC
Max. current load total	[A]	4
Operating conditions		
Ambient temperature	[°C]	-40...90
Protection		IP 68
Mechanical data		
Weight	[g]	430.912
Materials		TPU
Moulded-body material		TPU
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.
Electrical connection		
Cable: 10 m, PVC, black, Ø 5.3 mm; 5 x 0.34 mm² (19 x Ø 0.16 mm) / AWG 22		
Electrical connection - socket		
Connector: 1 x 1/2", straight; coding: C; Moulded body: TPU; Locking: brass, nickel-plated		




E18242



Connecting cable with socket

ADOGA050MSS0010A05

Connection

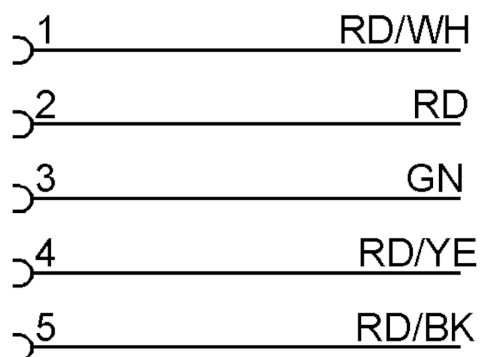

BK =	Core colours :	black
GN =		green
RD =		red
WH =		white
YE =		yellow