


Wirable plug

SSTGH080MSSFKPG

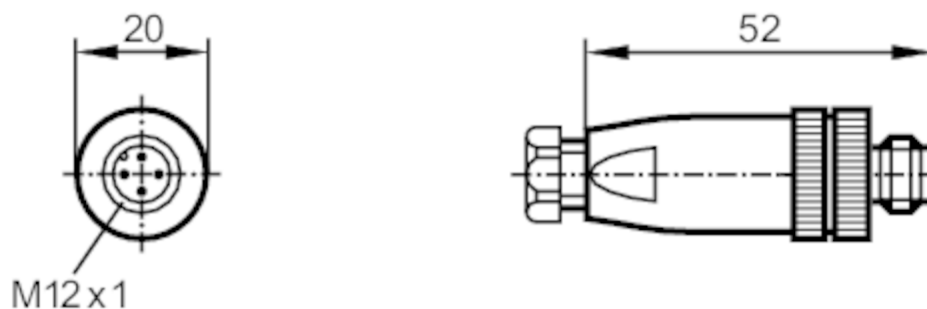

Application

Special feature	Free from silicone; Gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 125 AC/DC
Max. current load total	[A]	4; (...40 °C)

Operating conditions

Ambient temperature	[°C]	-25...100
Protection		IP 68

Mechanical data

Weight	[g]	23
Dimensions	[mm]	20 x 20 x 52
Materials		PA
Moulded-body material		PA
Material nut		brass, nickel-plated

Remarks

Pack quantity	1 pcs.
---------------	--------

E18343



Wirable plug


SSTGH080MSSFKPG

Electrical connection

terminals: ...0.75 mm²; Cable sheath: Ø 6...8 mm

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: PA; Locking: brass, nickel-plated; Contacts: gold-plated

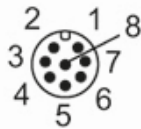

Connection

1	WH
2	BN
3	GN
4	YE
5	GY
6	PK
7	BU
8	RD