


E19938

Splitter box

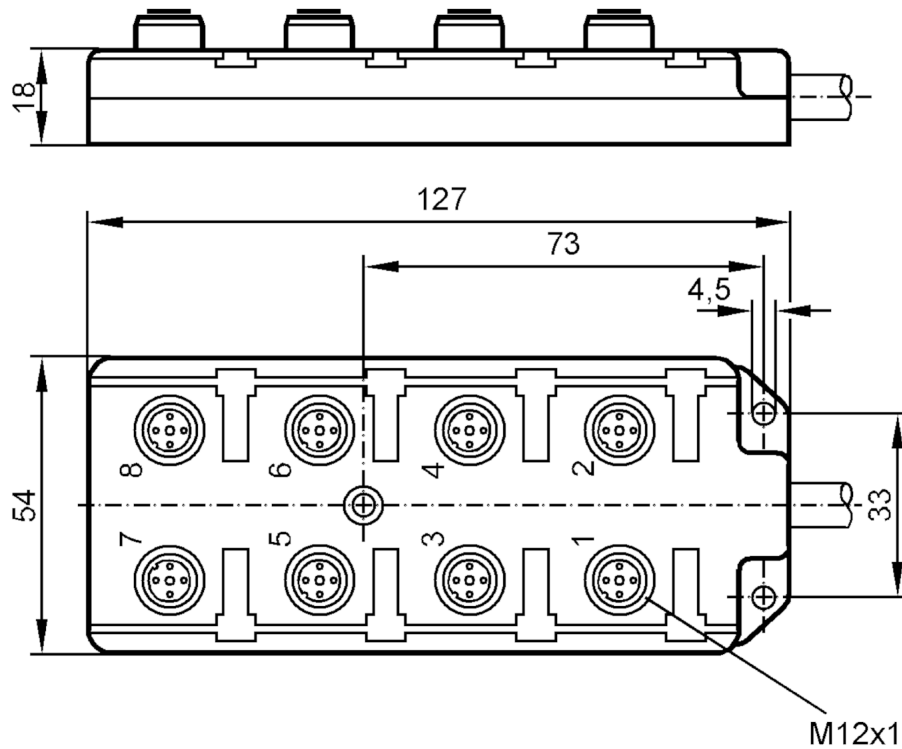

Electrical data

Operating voltage	[V]	10...110 AC/DC
Max. current load per module/slot	[A]	4
Max. current load total	[A]	12

Operating conditions

Ambient temperature	[°C]	-15...90
Protection		IP 67

Mechanical data

Dimensions	[mm]	16 x 54 x 127
Number of ports splitter box		8

Remarks

Pack quantity		1 pcs.
---------------	--	--------

Electrical connection


Cable: 5 m, PUR / PVC; 8 x 0.34 mm² + 3 x 0.75 mm²

Electrical connection - slot

Connector: 8 x M12

E19938

Splitter box

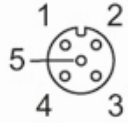

Connection

<u>BN</u>	1 (1...8)	C
<u>BU</u>	3 (1...8)	C
<u>GN/YE</u>	5 (1...8)	C
<u>WH</u>	4 (1)	C
<u>GN</u>	4 (2)	C
<u>YE</u>	4 (3)	C
<u>GY</u>	4 (4)	C
<u>PK</u>	4 (5)	C
<u>RD</u>	4 (6)	C
<u>BK</u>	4 (7)	C
<u>VT</u>	4 (8)	C

Core colours :

BK =	black
BN =	brown
BU =	blue
GN =	green
GN/YE =	green/yellow
GY =	grey
PK =	pink
RD =	red
VT =	lilac
WH =	white
YE =	yellow