


# E19939

## Splitter box

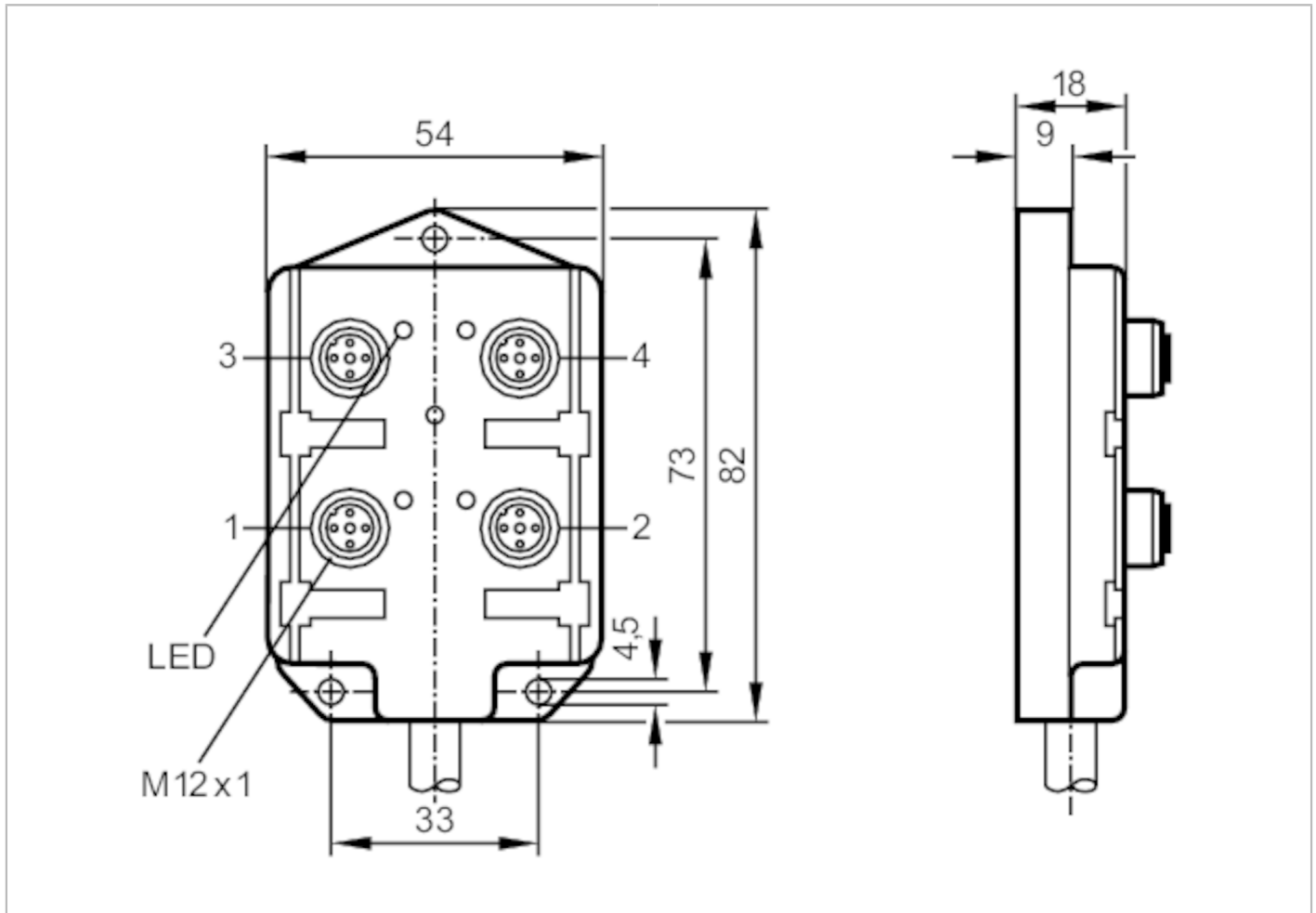

### Electrical data

Operating voltage	[V]	10...110 AC/DC
Max. current load per module/slot	[A]	4
Max. current load total	[A]	12

### Operating conditions

Ambient temperature	[°C]	-15...90
Protection		IP 67

### Mechanical data

Dimensions	[mm]	18 x 54 x 82
Number of ports splitter box		4

### Remarks

Pack quantity		1 pcs.
---------------	--	--------

### Electrical connection


Cable: 5 m, PUR / PVC; 4 x 0.34 mm<sup>2</sup> + 3 x 0.75 mm<sup>2</sup>

### Electrical connection - slot

Connector: 4 x M12

# E19939

## Splitter box

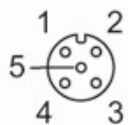

### Connection

<u>BN</u>	1 (1...4)	C
<u>BU</u>	3 (1...4)	C
<u>GN/YE</u>	5 (1...4)	C
<u>WH</u>	4 (1)	C
<u>GN</u>	4 (2)	C
<u>YE</u>	4 (3)	C
<u>GY</u>	4 (4)	C

#### Core colours :

BN =	brown
BU =	blue
GN =	green
GN/YE =	green/yellow
GY =	grey
WH =	white
YE =	yellow