


Fibre optic through-beam sensor

FE-00-M-V-E1/1m

Article no longer available - archive entry

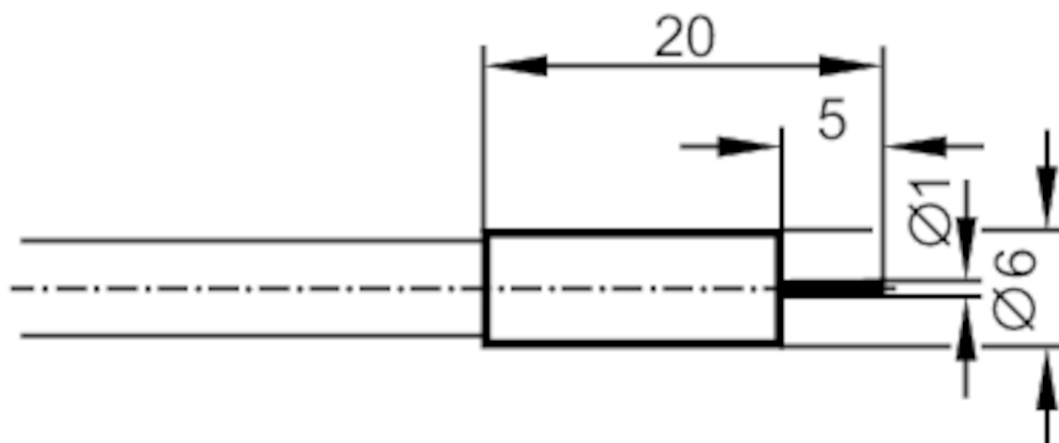

Application

Function principle

Through-beam sensor

Detection zone

Range with fibre-optic
amplifier type

OKF; OUF

OKF

Range of fibre optics

[mm]

50

OUF

Range of fibre optics

[mm]

50

Operating conditions

Ambient temperature

[°C]

-20...150

Mechanical data

Version of sensing head

straight

Sensing head diameter

[mm]

1

Sensing head length

[mm]

5

Total length

[mm]

1000

Min. bending radius

[mm]

20

Fibre material

glass

Fibre head material

stainless steel (303/1.4305)

E20539



Fibre optic through-beam sensor

FE-00-M-V-E1/1m

Fibre sheath material	metal silicone
Remarks	
Pack quantity	1 pcs.