


Fibre optic diffuse reflection sensor

FT-11-E-A-M6/F2X1/0,6M

Article no longer available - archive entry

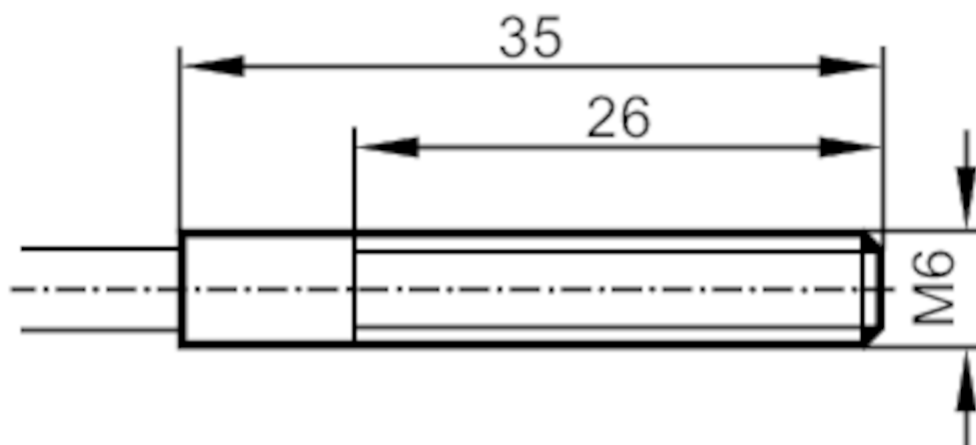

Application

Function principle

Diffuse reflection sensor

Detection zone

Range with fibre optic amplifier type

OBF

OBF

Range fibre optics

[mm]

70

Operating conditions

Ambient temperature

[°C]

-40...70

Mechanical data

Version of sensing head

straight

Sensing head thread

M6

Sensing head length

[mm]

35

Total length

[mm]

600

Min. bending radius

[mm]

30

Fibre material

PMMA

Fibre head material

aluminium

Fibre sheath material

PE

E20631



Fibre optic diffuse reflection sensor

FT-11-E-A-M6/F2X1/0,6M

Accessories	
Accessories (optional)	Cutter for fibre optics:, E20600
Remarks	
Pack quantity	1 pcs.