




Fibre optic diffuse reflection sensor

FT-50-V-V-R5

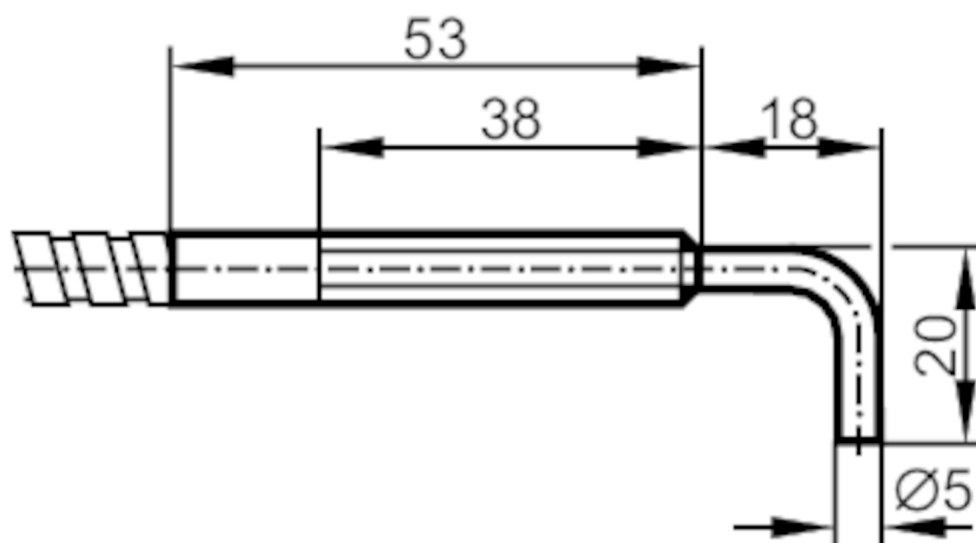

Application

Function principle	Diffuse reflection sensor
--------------------	---------------------------

Detection zone

Range with fibre optic amplifier type	OBF; ODF; OMF
---------------------------------------	---------------

OBF

Range fibre optics [mm]	150
-------------------------	-----

ODF

Range fibre optics [mm]	1
-------------------------	---

OMF

Range fibre optics [mm]	175
-------------------------	-----

Operating conditions

Ambient temperature [°C]	-58...315
--------------------------	-----------

Mechanical data

Weight [g]	126
Version of sensing head	angled
Sensing head diameter [mm]	5
Total length [mm]	900
Min. bending radius [mm]	19
Fibre arrangement	⊙

E20826



Fibre optic diffuse reflection sensor

FT-50-V-V-R5

Fibre material	glass
Fibre head material	stainless steel (303/1.4305)
Fibre sheath material	stainless steel (303/1.4305)
Accessories	
Items supplied	lock nuts: 2
	spring washers: 2
Remarks	
Pack quantity	1 pcs.