




Fibre optic through-beam sensor

FE-00-P-A-E2,5/2m

Article no longer available - archive entry

Alternative articles: E20359

When selecting an alternative article and accessories please note that technical data may differ!

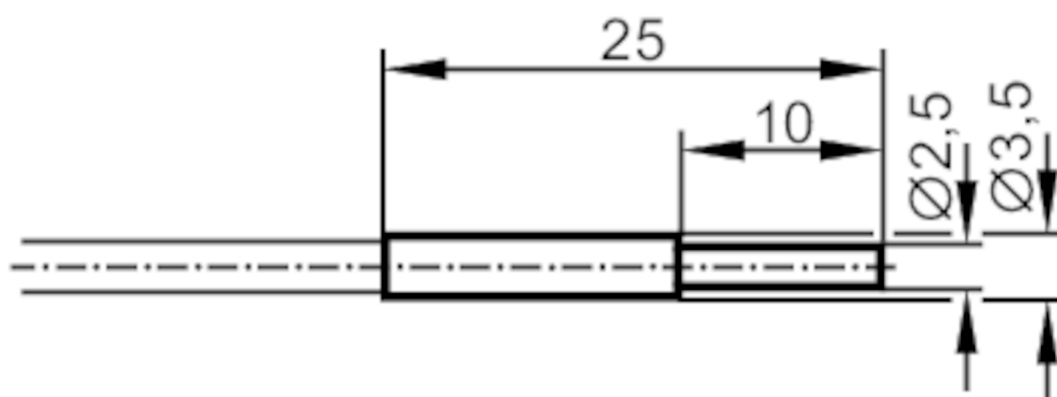

Application

Function principle

Through-beam sensor

Detection zone

Range with fibre-optic
amplifier type

OKF; OUF

OKF

Range of fibre optics

[mm]

96

OUF

Range of fibre optics

[mm]

96

Operating conditions

Ambient temperature

[°C]

-20...80

Mechanical data

Version of sensing head

straight

Sensing head diameter

[mm]

2.5

Sensing head length

[mm]

10

Total length

[mm]

2000

E20146



Fibre optic through-beam sensor

FE-00-P-A-E2,5/2m

Min. bending radius	[mm]	10
Materials	Adapter: PPE	
Fibre material	glass	
Fibre head material	aluminium	
Fibre sheath material	PVC	
Remarks		
Pack quantity	1 pcs.	