




Fibre optic diffuse reflection sensor

FT-00-A-A-R4/2,5M

Article no longer available - archive entry

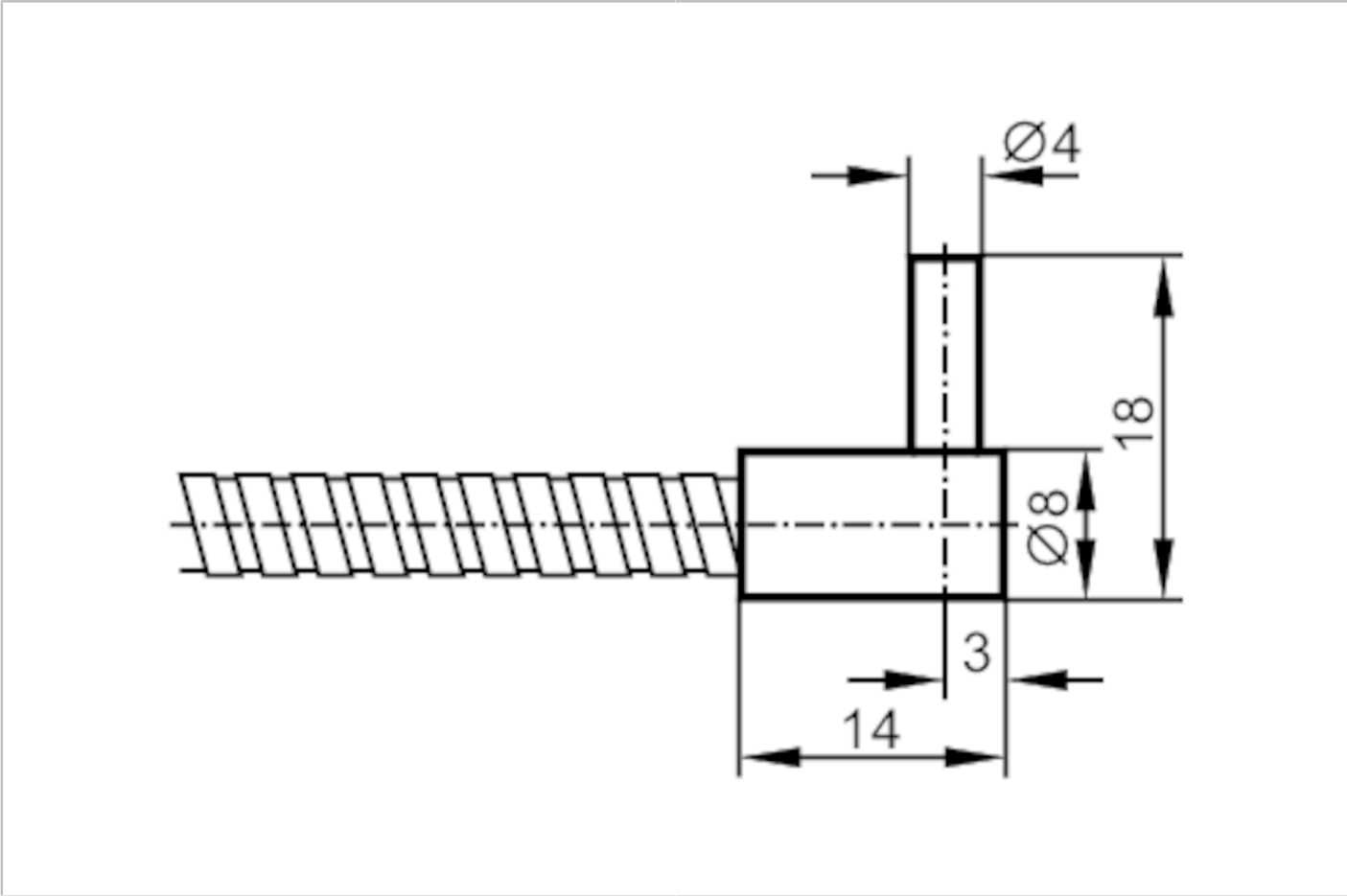

Application		
Function principle		Diffuse reflection sensor
Detection zone		
Range with fibre optic amplifier type		OKF; OUF
OKF		
Range fibre optics	[mm]	28
OUF		
Range fibre optics	[mm]	28
Operating conditions		
Ambient temperature	[°C]	-40...290
Mechanical data		
Version of sensing head		angled
Sensing head diameter	[mm]	4
Sensing head length	[mm]	10
Total length	[mm]	2500
Min. bending radius	[mm]	20
Materials		Adapter: ABS
Fibre material		glass

E20355



Fibre optic diffuse reflection sensor

FT-00-A-A-R4/2,5M

Fibre head material	aluminium
Fibre sheath material	aluminium
Remarks	
Pack quantity	1 pcs.