


Fibre optic through-beam sensor

FE-00-A-V-E1/2,5m

Article no longer available - archive entry

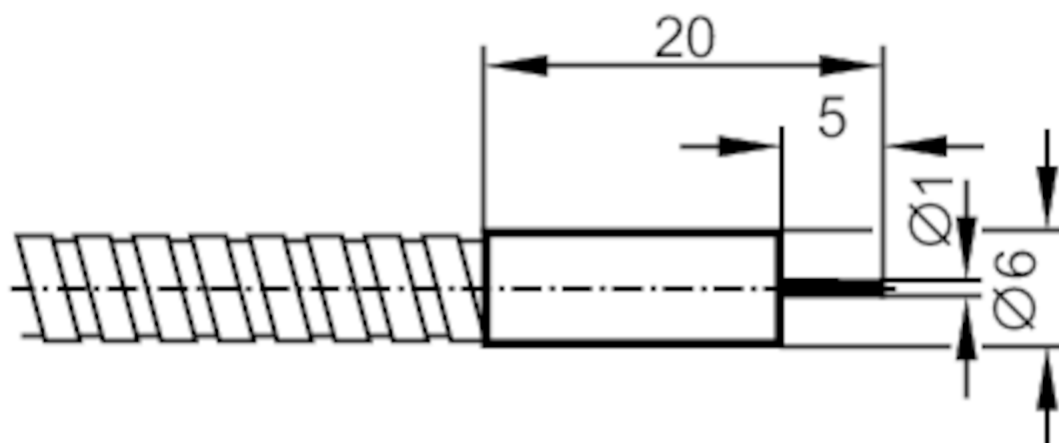

Application

Function principle

Through-beam sensor

Detection zone

Range with fibre-optic
amplifier type

OKF; OUF

OKF

Range of fibre optics

[mm]

36

OUF

Range of fibre optics

[mm]

36

Operating conditions

Ambient temperature

[°C]

-40...290

Mechanical data

Version of sensing head

straight

Sensing head diameter

[mm]

1

Sensing head length

[mm]

5

Total length

[mm]

2500

Min. bending radius

[mm]

20

Materials

Adapter: ABS

Fibre material

glass

E20372



Fibre optic through-beam sensor

FE-00-A-V-E1/2,5m

Fibre head material	stainless steel (1.4305 / 303)
Fibre sheath material	aluminium
Remarks	
Pack quantity	1 pcs.