




Fibre optic through-beam sensor

FE-18-P-A-R4

Article no longer available - archive entry

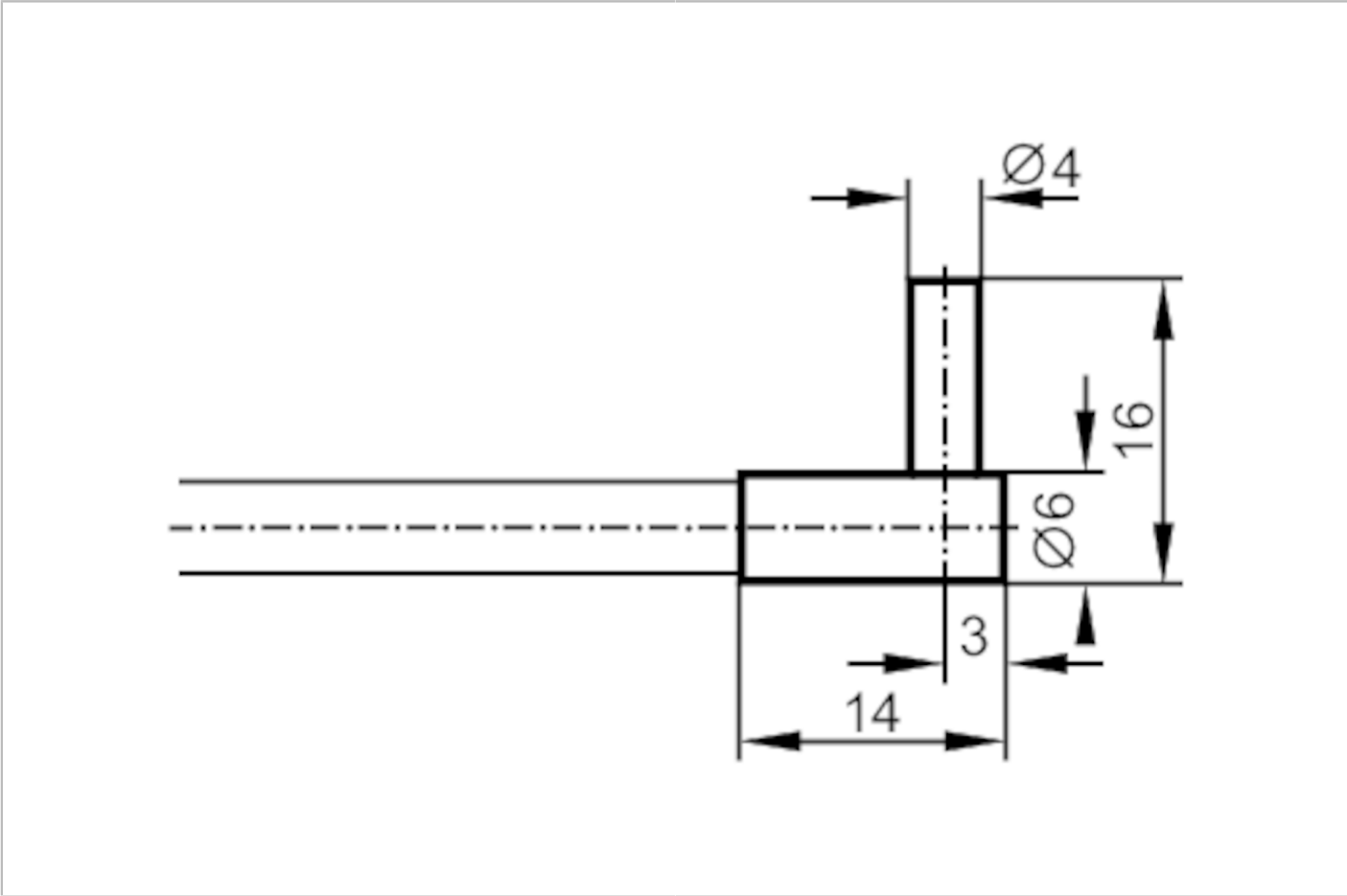

Application		
Function principle		Through-beam sensor
Detection zone		
Range with fibre-optic amplifier type		OGF
OGF		
Range of fibre optics	[mm]	80
Operating conditions		
Ambient temperature	[°C]	-20...80
Mechanical data		
Weight	[g]	63.4
Version of sensing head		angled
Sensing head diameter	[mm]	4
Sensing head length	[mm]	10
Total length	[mm]	600
Min. bending radius	[mm]	20
Fibre arrangement		●
Materials		Adapter: PPE
Fibre material		glass

E20388



Fibre optic through-beam sensor

FE-18-P-A-R4

Fibre head material	aluminium
Fibre sheath material	PVC
Accessories	
Items supplied	E20103
Remarks	
Pack quantity	1 pcs.